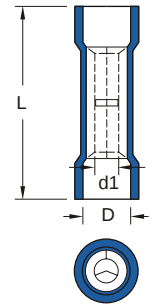


VINYL-INSULATED BUTT SPLICE CONNECTORS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50

MAXIMUM ELECTRICAL RATING: 75°C 600 VOLTS MAX.
CONNECTOR MATERIAL: COPPER
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
INSULATION MATERIAL: VINYL


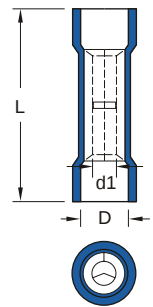
WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION ^{inch} mm			MATERIAL	CRIMPING TOOL	Q'TY BOX
		L	D	d1			
22-16 A.W.G. 0.5-1.5 mm ²	BV1 *	.969 24.6	.157 4.0	.067 1.7	COPPER PLATE	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
16-14 A.W.G. 1.5-2.5 mm ²	BV2 *	.969 24.6	.177 4.5	.091 2.3	COPPER PLATE	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
12-10 A.W.G. 4-6 mm ²	BV5 *	1.043 26.5	.248 6.3	.134 3.4	COPPER PLATE	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500

VINYL-INSULATED BUTT SPLICE CONNECTORS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

MAXIMUM ELECTRICAL RATING: 75°C 300 VOLTS MAX.
CONNECTOR MATERIAL: BRASS
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
INSULATION MATERIAL: VINYL


WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION ^{inch} mm			MATERIAL	CRIMPING TOOL	Q'TY BOX
		L	D	d1			
22-16 A.W.G. 0.5-1.5 mm ²	BVS1	.969 24.6	.157 4.0	.067 1.7	BRASS PLATE	K.S. MODEL KST2000C WITH DIE INDEX COLOR:RED	1000
	BVS1-0.45			.089 2.25			
16-14 A.W.G. 1.5-2.5 mm ²	BVS2	.969 24.6	.177 4.5	.098 2.5	BRASS PLATE	K.S. MODEL KST2000C WITH DIE INDEX COLOR:BLUE	1000
	BVS2-0.45			.112 2.85			
12-10 A.W.G. 4-6 mm ²	BVS5	1.043 26.5	.248 6.3	.134 3.4	BRASS PLATE	K.S. MODEL KST2000C WITH DIE INDEX COLOR:YELLOW	500
22-16 A.W.G. 0.5-1.5 mm ²	BVSB1	.969 24.6	.157 4.0	.071 1.8	BRASS PLATE	K.S. MODEL KST2000A WITH DIE INDEX COLOR:RED	1000
16-14 A.W.G. 1.5-2.5 mm ²	BVSB2	.969 24.6	.177 4.5	.098 2.5	BRASS PLATE	K.S. MODEL KST2000A WITH DIE INDEX COLOR:BLUE	1000
12-10 A.W.G. 4-6 mm ²	BVSB5	1.043 26.5	.248 6.3	.130 3.3	BRASS PLATE	K.S. MODEL KST2000A WITH DIE INDEX COLOR:YELLOW	500



ALL LISTED

* :ADDITIONAL CERTIFIED