

VINYL-INSULATED (EASY ENTRY) BLADE TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14
AMP.	9	12	17	18	30


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

INSULATION COLOR:

22-16 A.W.G.: RED 16-14 A.W.G.: BLUE

TERMINAL MATERIAL: COPPER

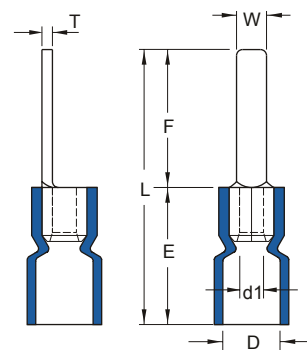

WIRE RANGE A.W.G. mm ²	ITEM NO.		DIMENSION inch mm							CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	W	F	L	E	D	d1	T		
22-16 A.W.G. 0.5-1.5 mm ²	DBVEB1-9	DBVE1-9	.110 2.8	.354 9.0	.787 20.0	.441 11.2	.157 4.0	.067 1.7	.030 0.75	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	DBVEB1-10	DBVE1-10	.091 2.3	.394 10.0	.827 21.0						1000
	DBVEB1-11	DBVE1-11	.118 3.0	.433 11.0	.906 23.0						1000
	DBVEBS1-13	DBVES1-13	.075 1.9	.512 13.0	.945 24.0						1000
	DBVEB1-13	DBVE1-13	.118 3.0								1000
	DBVEB1-14	DBVE1-14	.118 3.0	.551 14.0	.984 25.0						1000
	DBVEB1-18	DBVE1-18	.087 2.2	.709 18.0	1.142 29.0						1000
	DBVEBS1-18	DBVES1-18	.079 2.0								1000
16-14 A.W.G. 1.5-2.5 mm ²	DBVEB2-9	DBVE2-9	.110 2.8	.354 9.0	.799 20.3	.453 11.5	.177 4.5	.091 2.3	.031 0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	DBVEB2-10	DBVE2-10	.094 2.4	.394 10.0	.839 21.3						1000
	DBVEB2-13	DBVE2-13	.094 2.4								1000
	DBVEBL2-13	DBVEL2-13	.118 3.0	.512 13.0	.957 24.3						1000
	DBVEBLL2-13	DBVELL2-13	.177 4.5								1000
	DBVEBS2-14	DBVES2-14	.827 2.1								1000
	DBVEB2-14	DBVE2-14	.094 2.4	.551 14.0	.996 25.3						1000
	DBVEBL2-14	DBVEL2-14	.118 3.0								1000
	DBVEBS2-18	DBVES2-18	.079 2.0								1000
	DBVEB2-18	DBVE2-18	.087 2.2	.709 18.0	1.154 29.3						1000
	DBVEBL2-18	DBVEL2-18	.110 2.8								1000

UL cUL ALL LISTED