

**DIN 46237**

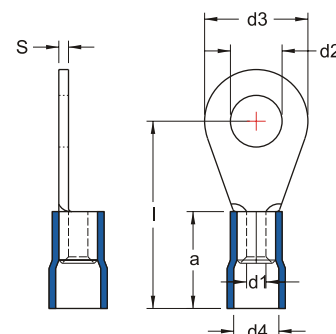
# VINYL-INSULATED RING TERMINALS

**MAXIMUM ELECTRIC CURRENT:**

|        |    |    |    |    |     |
|--------|----|----|----|----|-----|
| A.W.G. | 12 | 10 | 8  | 6  | 4   |
| AMP.   | 35 | 50 | 70 | 95 | 125 |

**MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.**
**INSULATION MATERIAL: VINYL**
**INSULATION COLOR:**

 12-10 A.W.G.: YELLOW  8 A.W.G.: RED  6 A.W.G.: BLUE 

 4 A.W.G.: YELLOW 
**TERMINAL MATERIAL: COPPER**


| WIRE RANGE<br>A.W.G.<br>mm <sup>2</sup>      | ITEM NO.             |                     | STUD SIZE |      | DIMENSION mm |      |     |      |      |     | CRIMPING TOOL                                                                                                                                                        | Q'TY BOX |      |     |
|----------------------------------------------|----------------------|---------------------|-----------|------|--------------|------|-----|------|------|-----|----------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------|------|-----|
|                                              | BRAZED SEAM          | BUTTED SEAM         | d2        |      | d3           | I    | d1  | d4   | a    | S   |                                                                                                                                                                      |          |      |     |
| 12-10<br>A.W.G.<br><br>2.5-6 mm <sup>2</sup> | DRVB3-6 <sup>⊙</sup> | DRV3-6 <sup>⊙</sup> | #4        | 3.2  | 6.0          | 21.0 | 3.6 | 6.3  | 13.0 | 1.0 | IZUMI MODEL 5<br>WITH DIE INDEX<br>COLOR:YELLOW<br><br>OR<br>K.S. MODEL<br>KST2000A<br><b>HRI-126J</b><br>KSTLY-2004<br>KSTLY-2005<br>WITH DIE INDEX<br>COLOR:YELLOW | 500      |      |     |
|                                              | DRVB4-6              | DRV4-6              | #8        | 4.3  | 8.0          | 21.0 |     |      |      |     |                                                                                                                                                                      | 500      |      |     |
|                                              | DRVB5-6              | DRV5-6              | #10       | 5.3  | 10.0         | 22.0 |     |      |      |     |                                                                                                                                                                      | 500      |      |     |
|                                              | DRVB6-6              | DRV6-6              | 1/4       | 6.5  | 11.0         | 22.5 |     |      |      |     |                                                                                                                                                                      | 500      |      |     |
|                                              | DRVB8-6              | DRV8-6              | 5/16      | 8.4  | 14.0         | 26.0 |     |      |      |     |                                                                                                                                                                      | 500      |      |     |
|                                              | DRVB10-6             | DRV10-6             | 3/8       | 10.5 | 18.0         | 28.0 |     |      |      |     |                                                                                                                                                                      | 500      |      |     |
|                                              | DRVB12-6             | DRV12-6             | 1/2       | 13.0 |              |      |     |      |      |     |                                                                                                                                                                      | 500      |      |     |
| 8<br><br>A.W.G.<br><br>10 mm <sup>2</sup>    | DRVB4-10             |                     | #8        | 4.3  | 10.0         | 24.5 | 4.5 | 8.0  | 16.5 | 1.1 |                                                                                                                                                                      | 500      |      |     |
|                                              | DRVB5-10             |                     | #10       | 5.3  |              |      |     |      |      |     |                                                                                                                                                                      | 500      |      |     |
|                                              | DRVB6-10             |                     | 1/4       | 6.5  |              |      |     |      |      |     |                                                                                                                                                                      | 11.0     | 25.5 | 500 |
|                                              | DRVB8-10             |                     | 5/16      | 8.4  |              |      |     |      |      |     |                                                                                                                                                                      | 14.0     | 28.5 | 500 |
|                                              | DRVB10-10            |                     | 3/8       | 10.5 |              |      |     |      |      |     |                                                                                                                                                                      | 18.0     | 29.5 | 250 |
|                                              | DRVB12-10            |                     | 1/2       | 13.0 |              |      |     |      |      |     |                                                                                                                                                                      | 22.0     | 31.5 | 250 |
| 6<br><br>A.W.G.<br><br>16 mm <sup>2</sup>    | DRVB5-16             |                     | #10       | 5.3  | 11.0         | 31.5 | 5.8 | 10.5 | 21.5 | 1.2 |                                                                                                                                                                      | 250      |      |     |
|                                              | DRVB6-16             |                     | 1/4       | 6.5  |              |      |     |      |      |     |                                                                                                                                                                      | 100      |      |     |
|                                              | DRVB8-16             |                     | 5/16      | 8.4  |              |      |     |      |      |     |                                                                                                                                                                      | 14.0     | 33.5 | 100 |
|                                              | DRVB10-16            |                     | 3/8       | 10.5 |              |      |     |      |      |     |                                                                                                                                                                      | 18.0     | 35.5 | 100 |
|                                              | DRVB12-16            |                     | 1/2       | 13.0 |              |      |     |      |      |     |                                                                                                                                                                      | 22.0     | 37.5 | 100 |
| 4<br><br>A.W.G.<br><br>25 mm <sup>2</sup>    | DRVB5-25             |                     | #10       | 5.3  | 12.0         | 38.0 | 7.5 | 13.0 | 24.0 | 1.5 |                                                                                                                                                                      | 100      |      |     |
|                                              | DRVB6-25             |                     | 1/4       | 6.5  |              |      |     |      |      |     |                                                                                                                                                                      | 100      |      |     |
|                                              | DRVB8-25             |                     | 5/16      | 8.4  |              |      |     |      |      |     |                                                                                                                                                                      | 16.0     | 100  |     |
|                                              | DRVB10-25            |                     | 3/8       | 10.5 |              |      |     |      |      |     |                                                                                                                                                                      | 18.0     | 39.0 | 100 |
|                                              | DRVB12-25            |                     | 1/2       | 13.0 |              |      |     |      |      |     |                                                                                                                                                                      | 22.0     | 44.0 | 100 |
|                                              | DRVB16-25            |                     | 5/8       | 17.0 |              |      |     |      |      |     |                                                                                                                                                                      | 28.0     | 48.0 | 100 |



ALL LISTED

⊙: NOT UL AND C-UL LISTED