

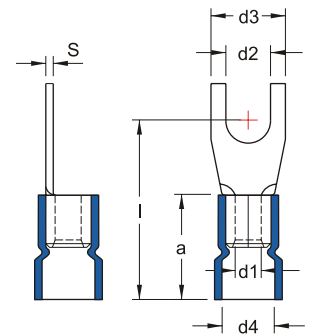
DIN 46237

# VINYL-INSULATED (EASY ENTRY) SPADE TERMINALS

**MAXIMUM ELECTRIC CURRENT:**

|        |    |    |    |    |    |    |    |
|--------|----|----|----|----|----|----|----|
| A.W.G. | 22 | 20 | 18 | 16 | 14 | 12 | 10 |
| AMP.   | 9  | 12 | 17 | 18 | 30 | 35 | 50 |

**MAXIMUM ELECTRICAL RATING: 75°C 600 VOLTS MAX.**
**INSULATION MATERIAL: VINYL**
**INSULATION COLOR:**

 22-16 A.W.G.: RED  16-14 A.W.G.: BLUE  12-10 A.W.G.: YELLOW 
**TERMINAL MATERIAL: COPPER**


| WIRE RANGE<br>A.W.G.<br>mm <sup>2</sup>           | ITEM NO.     |             | STUD SIZE |      | DIMENSION mm |      |     |     |      |     | CRIMPING TOOL                                                                                                                            | Q'TY BOX |
|---------------------------------------------------|--------------|-------------|-----------|------|--------------|------|-----|-----|------|-----|------------------------------------------------------------------------------------------------------------------------------------------|----------|
|                                                   | BRAZED SEAM  | BUTTED SEAM | d2        |      | d3           | l    | d1  | d4  | a    | S   |                                                                                                                                          |          |
| 22-16<br>A.W.G.<br><br>0.5-1.5<br>mm <sup>2</sup> | DSVEB3-1     | DSVE3-1     | #4        | 3.2  | 6.0          | 17.2 | 1.6 | 4.0 | 11.2 | 0.8 | IZUMI MODEL 34<br>WITH DIE INDEX<br>COLOR:RED<br><br>OR<br>K.S. MODEL<br>KST2000A<br><b>HRI-126J</b><br>WITH DIE INDEX<br>COLOR:RED      | 1000     |
|                                                   | DSVEB3.5-1   | DSVE3.5-1   | #6        | 3.7  |              |      |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEB4-1     | DSVE4-1     | #8        | 4.3  | 6.8          | 18.2 |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEBL4-1    | DSVEL4-1    | #8        | 4.3  |              |      |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEB5-1     | DSVE5-1     | #10       | 5.3  | 10.0         | 19.2 |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEB6-1     | DSVE6-1     | 1/4       | 6.5  | 11.0         | 21.2 |     |     |      |     |                                                                                                                                          | 1000     |
| 16-14<br>A.W.G.<br><br>1.5-2.5<br>mm <sup>2</sup> | DSVEB3-2.5   | DSVE3-2.5   | #4        | 3.2  | 5.5          | 19.5 | 2.3 | 4.5 | 11.5 | 0.8 | IZUMI MODEL 34<br>WITH DIE INDEX<br>COLOR:BLUE<br><br>OR<br>K.S. MODEL<br>KST2000A<br><b>HRI-126J</b><br>WITH DIE INDEX<br>COLOR:BLUE    | 1000     |
|                                                   | DSVEB3.5-2.5 | DSVE3.5-2.5 | #6        | 3.7  | 6.0          | 17.5 |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEB4-2.5   | DSVE4-2.5   | #8        | 4.3  | 6.8          | 18.5 |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEBL4-2.5  | DSVEL4-2.5  | #8        | 4.3  | 8.0          |      |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEB5-2.5   | DSVE5-2.5   | #10       | 5.3  | 10.0         | 20.5 |     |     |      |     |                                                                                                                                          | 1000     |
|                                                   | DSVEB6-2.5   | DSVE6-2.5   | 1/4       | 6.5  | 11.0         | 22.5 |     |     |      |     |                                                                                                                                          | 1000     |
| 12-10<br>A.W.G.<br><br>2.5-6<br>mm <sup>2</sup>   | DSVEB4-6     | DSVE4-6     | #8        | 4.3  | 8.0          | 22.1 | 3.6 | 6.3 | 14.1 | 1.0 | IZUMI MODEL 5<br>WITH DIE INDEX<br>COLOR:YELLOW<br><br>OR<br>K.S. MODEL<br>KST2000A<br><b>HRI-126J</b><br>WITH DIE INDEX<br>COLOR:YELLOW | 500      |
|                                                   | DSVEB5-6     | DSVE5-6     | #10       | 5.3  | 10.0         | 23.1 |     |     |      |     |                                                                                                                                          | 500      |
|                                                   | DSVEB6-6     | DSVE6-6     | 1/4       | 6.5  | 11.0         | 24.1 |     |     |      |     |                                                                                                                                          | 500      |
|                                                   | DSVEB8-6     | DSVE8-6     | 5/16      | 8.4  | 14.0         | 27.1 |     |     |      |     |                                                                                                                                          | 500      |
|                                                   | DSVEB10-6    | DSVE10-6    | 3/8       | 10.5 | 18.0         | 29.1 |     |     |      |     |                                                                                                                                          | 500      |

UL cUL ALL LISTED