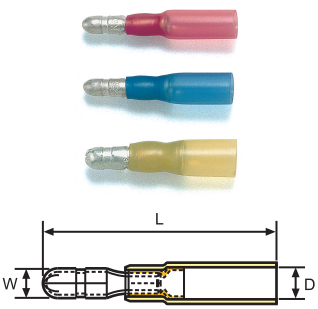
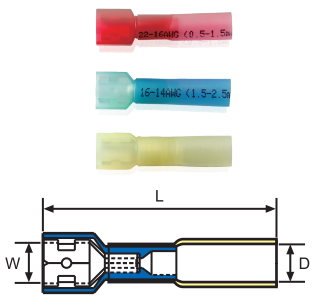


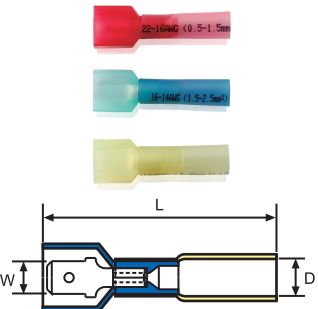
## PE-HEAT SHRINKABLE-BULLET DISCONNECTS “HD” ( DOUBLE CRIMP TYPE )

|  | WIRE RANGE<br>A.W.G. / MM <sup>2</sup> | ITEM NO.  | W   | D   | L    | INSULATED<br>COLOR |
|-----------------------------------------------------------------------------------|----------------------------------------|-----------|-----|-----|------|--------------------|
|                                                                                   | 22-16 / 0.5-1.5                        | MPHD1-156 | 4.0 | 5.5 | 33.0 | RED                |
|                                                                                   | 16-14 / 1.5-2.5                        | MPHD2-156 | 4.0 | 6.0 | 33.0 | BLUE               |
|                                                                                   |                                        | MPHD2-195 | 5.0 |     |      |                    |
|                                                                                   | 12-10 / 4-6                            | MPHD5-196 | 5.0 | 8.1 | 35.5 | YELLOW             |

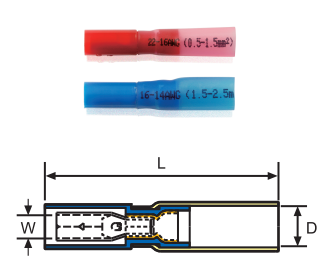
## PE-HEAT SHRINKABLE-FULLY NYLON FEMALE DISCONNECTS “H” ( TUBULAR TYPE )

|  | WIRE RANGE<br>A.W.G. / MM <sup>2</sup> | ITEM NO.     | NEMA TAB<br>IN<br>mm      | W   | D   | L    | INSULATED<br>COLOR |
|-----------------------------------------------------------------------------------|----------------------------------------|--------------|---------------------------|-----|-----|------|--------------------|
|                                                                                   | 22-16 / 0.5-1.5                        | FDFNYH 1-250 | .032 x .250<br>0.8 x 6.35 | 6.6 | 6.5 | 36.5 | RED                |
|                                                                                   | 16-14 / 1.5-2.5                        | FDFNYH 2-250 |                           |     |     |      | BLUE               |
|                                                                                   | 12-10 / 4-6                            | FDFNYH 5-250 |                           |     | 7.5 | 37.0 | YELLOW             |

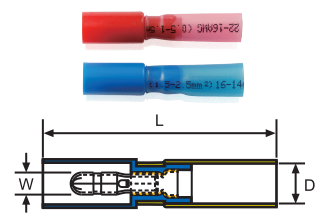
## PE-HEAT SHRINKABLE-FULLY NYLON MALE DISCONNECTS “H” ( SINGLE CRIMP TYPE )

|  | WIRE RANGE<br>A.W.G. / MM <sup>2</sup> | ITEM NO.     | NEMA TAB<br>IN<br>mm      | W    | D   | L    | INSULATED<br>COLOR |
|-------------------------------------------------------------------------------------|----------------------------------------|--------------|---------------------------|------|-----|------|--------------------|
|                                                                                     | 22-16 / 0.5-1.5                        | MDFNYH 1-250 | .032 x .250<br>0.8 x 6.35 | 6.35 | 6.5 | 38.5 | RED                |
|                                                                                     | 16-14 / 1.5-2.5                        | MDFNYH 2-250 |                           |      |     | 39.5 | BLUE               |
|                                                                                     | 12-10 / 4-6                            | MDFNYH 5-250 |                           |      | 7.5 |      | YELLOW             |

## PE-HEAT SHRINKABLE-FULLY NYLON RECEPTACLE DISCONNECTS “HD” ( DOUBLE CRIMP TYPE )

|  | WIRE RANGE<br>A.W.G. / MM² | ITEM NO.     | W   | D   | L    | INSULATED<br>COLOR |
|-------------------------------------------------------------------------------------|----------------------------|--------------|-----|-----|------|--------------------|
|                                                                                     | 22-16 / 0.5-1.5            | FRFNYDH1-156 | 3.9 | 6.5 | 40.5 | RED                |
|                                                                                     | 16-14 / 1.5-2.5            | FRFNYDH2-156 |     | 7.5 |      | 42.5               |
|                                                                                     |                            | FRFNYDH2-195 | 4.9 |     |      |                    |

## PE-HEAT SHRINKABLE-FULLY NYLON BULLET DISCONNECTORS “HD” ( DOUBLE CRIMP TYPE )

|  | WIRE RANGE<br>A.W.G. / MM <sup>2</sup> | ITEM NO.     | W   | D   | L    | INSULATED<br>COLOR |
|-------------------------------------------------------------------------------------|----------------------------------------|--------------|-----|-----|------|--------------------|
|                                                                                     | 22-16 / 0.5-1.5                        | MPFNYDH1-156 | 4.0 | 6.3 | 42.0 | RED                |
|                                                                                     | 16-14 / 1.5-2.5                        | MPFNYDH2-156 |     | 7.3 |      | BLUE               |