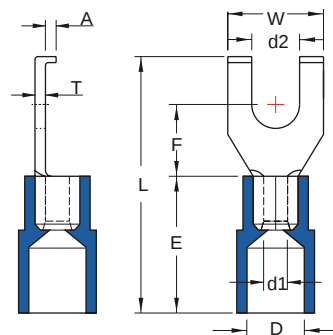


NYLON-INSULATED FLANGE SPADE TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: NYLON
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
TERMINAL MATERIAL: COPPER


WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION ^{inch} mm								CRIMPING TOOL	Q'TY BOX	
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	A	T			
22-16 A.W.G. 0.5-1.5 mm ²	FSNYBS1-2	FSNYS1-2	#2	.087 2.2	.252 6.4	.205 5.2	.787 20.0	.433 11.0	.157 4.0	.067 1.7	.059 1.5	.030 0.75	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000	
	FSNYB1-3.2	FSNY1-3.2	#4	.126 3.2	.295 7.5	.201 5.1								1000	
	FSNYBS1-3.2	FSNYS1-3.2	#4	.126 3.2	.252 6.4									1000	
	FSNYB1-3.7	FSNY1-3.7	#6	.146 3.7	.295 7.5									1000	
	FSNYBS1-3.7	FSNYS1-3.7	#6	.146 3.7	.252 6.4									1000	
	FSNYBL1-3.7	FSNYL1-3.7	#6	.146 3.7	.335 8.5	.283 7.2								1.004 25.5	1000
	FSNYB1-4	FSNY1-4	#8	.169 4.3	.295 7.5	.201 5.1								.787 20.0	1000
	FSNYBL1-4	FSNYL1-4	#8	.169 4.3	.335 8.5	.283 7.2								1.004 25.5	1000
	FSNYB1-5	FSNY1-5	#10	.209 5.3	.295 7.5	.201 5.1								.787 20.0	1000
	FSNYBL1-5	FSNYL1-5	#10	.209 5.3	.335 8.5	.283 7.2								1.004 25.5	1000
16-14 A.W.G. 1.5-2.5 mm ²	FSNYB2-3.7	FSNY2-3.7	#6	.146 3.7	.295 7.5	.205 5.2	.807 20.5	.433 11.0	.177 4.5	.091 2.3	.059 1.5	.031 0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000	
	FSNYBL2-3.7	FSNYL2-3.7	#6	.146 3.7	.335 8.5	.283 7.2	.945 24.0							1000	
	FSNYB2-4	FSNY2-4	#8	.169 4.3	.295 7.5	.205 5.2	.807 20.5							1000	
	FSNYBM2-4	FSNYM2-4	#8	.169 4.3	.315 8.0	.268 6.8	.965 24.5							1000	
	FSNYBL2-4	FSNYL2-4	#8	.169 4.3	.335 8.5	.283 7.2	.945 24.0							1000	
	FSNYB2-5	FSNY2-5	#10	.209 5.3	.295 7.5	.205 5.2	.807 20.5							1000	
	FSNYBL2-5	FSNYL2-5	#10	.209 5.3	.335 8.5	.283 7.2	.945 24.0							1000	
12-10 A.W.G. 4-6 mm ²	FSNYB5-3.7	FSNY5-3.7	#6	.146 3.7	.335 8.5	.295 7.5	1.063 27.0	.512 13.0	.252 6.4	.134 3.4	.059 1.5	.039 1.0	IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500	
	FSNYBS5-3.7	FSNYS5-3.7	#6	.146 3.7	.299 7.6	.244 6.2	1.004 25.5							500	
	FSNYB5-4	FSNY5-4	#8	.169 4.3	.335 8.5	.295 7.5	1.063 27.0							500	
	FSNYBS5-4	FSNYS5-4	#8	.169 4.3	.299 7.6	.244 6.2	1.004 25.5							500	
	FSNYB5-5	FSNY5-5	#10	.209 5.3	.335 8.5	.295 7.5	1.063 27.0							500	
	FSNYBS5-5	FSNYS5-5	#10	.209 5.3	.299 7.6	.244 6.2	1.004 25.5							500	

(UL) (UL) ALL LISTED