

# NYLON-INSULATED HOOK TERMINALS

**MAXIMUM ELECTRIC CURRENT:**

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50


**MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.**

**INSULATION MATERIAL: NYLON**

**INSULATION COLOR:**

22-16 A.W.G.: RED ■    16-14 A.W.G.: BLUE ■    12-10 A.W.G.: YELLOW ■

**TERMINAL MATERIAL: COPPER**

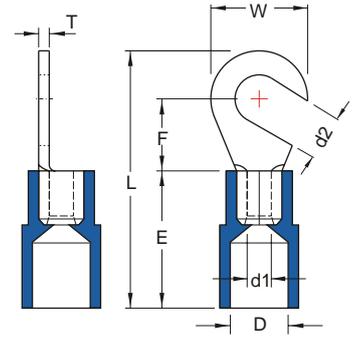

WIRE RANGE A.W.G. mm <sup>2</sup>	ITEM NO.		STUD SIZE		DIMENSION <small>inch mm</small>							CRIMPING TOOL	Q'TY BOX	
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	T			
22-16 A.W.G. 0.5-1.5 mm <sup>2</sup>	HNYB1-3.7	HNY1-3.7	#6	.146 3.7									IZUMI MODEL 34 WITH DIE INDEX COLOR:RED  OR K.S. MODEL KST2000A <b>HRI-126J</b> WITH DIE INDEX COLOR:RED	1000
	HNYB1-4	HNY1-4	#8	.169 4.3	.315 8.0	.276 7.0	.858 21.8							1000
	HNYB1-5	HNY1-5	#10	.209 5.3				.433 11.0	.157 4.0	.067 1.7	.030 0.75			1000
	HNYB1-6	HNY1-6	1/4	.252 6.4	.457 11.6	.433 11.0	1.094 27.8							1000
16-14 A.W.G. 1.5-2.5 mm <sup>2</sup>	HNYB2-3.7	HNY2-3.7	#6	.146 3.7									IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE  OR K.S. MODEL KST2000A <b>HRI-126J</b> WITH DIE INDEX COLOR:BLUE	1000
	HNYB2-4	HNY2-4	#8	.169 4.3	.335 8.5	.291 7.4	.898 22.8							1000
	HNYB2-5	HNY2-5	#10	.209 5.3	.374 9.5	.287 7.3		.433 11.0	.177 4.5	.091 2.3	.031 0.8			1000
	HNYB2-6	HNY2-6	1/4	.252 6.4	.472 12.0	.433 11.0	1.094 27.8							1000
12-10 A.W.G. 4-6 mm <sup>2</sup>	HNYB5-3.7	HNY5-3.7	#6	.146 3.7	.283 7.2	.240 6.1	.894 22.7						IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW  OR K.S. MODEL KST2000A <b>HRI-126J</b> WITH DIE INDEX COLOR:YELLOW	500
	HNYB5-4	HNY5-4	#8	.169 4.3										500
	HNYB5-5	HNY5-5	#10	.209 5.3	.374 9.5	.374 9.5	1.055 26.8							500
	HNYB5-6	HNY5-6	1/4	.252 6.4	.472 12.0	.406 10.3	1.161 29.5	.512 13.0	.252 6.4	.134 3.4	.039 1.0			500
	HNYB5-8	HNY5-8	5/16	.331 8.4	.591 15.0	.531 13.5	1.339 34.0							500

UL cUL ALL LISTED

