

VINYL-INSULATED (EASY ENTRY) HOOK TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

INSULATION COLOR:

22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW

TERMINAL MATERIAL: COPPER

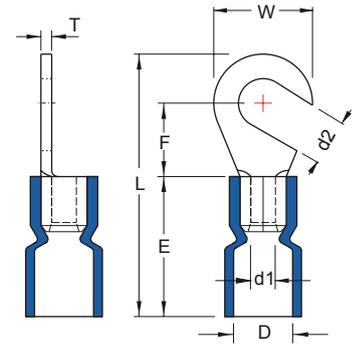

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION <small>inch mm</small>							CRIMPING TOOL	Q'TY BOX	
	BRAZED SEAM	BUTTED SEAM	d2		W	F	L	E	D	d1	T			
22-16 A.W.G. 0.5-1.5 mm ²	HVEB1-3.7	HVE1-3.7	#6	.146 3.7									IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	HVEB1-4	HVE1-4	#8	.169 4.3	.315 8.0	.276 7.0	.866 22.0	.441 11.2	.157 4.0	.067 1.7	.030 0.75	1000		
	HVEB1-5	HVE1-5	#10	.209 5.3								1000		
	HVEB1-6	HVE1-6	1/4	.252 6.4	.457 11.6	.433 11.0	1.102 28.0					1000		
16-14 A.W.G. 1.5-2.5 mm ²	HVEB2-3.7	HVE2-3.7	#6	.146 3.7									IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	HVEB2-4	HVE2-4	#8	.169 4.3	.335 8.5	.291 7.4	.917 23.3	.453 11.5	.177 4.5	.091 2.3	.031 0.8	1000		
	HVEB2-5	HVE2-5	#10	.209 5.3	.374 9.5	.287 7.3						1000		
	HVEB2-6	HVE2-6	1/4	.252 6.4	.472 12.0	.433 11.0	1.114 28.3					1000		
12-10 A.W.G. 4-6 mm ²	HVEB5-3.7	HVE5-3.7	#6	.146 3.7	.283 7.2	.240 6.1	.937 23.8						IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
	HVEB5-4	HVE5-4	#8	.169 4.3								500		
	HVEB5-5	HVE5-5	#10	.209 5.3	.374 9.5	.374 9.5	1.098 27.9	.555 14.1	.248 6.3	.134 3.4	.039 1.0	500		
	HVEB5-6	HVE5-6	1/4	.252 6.4	.472 12.0	.406 10.3	1.205 30.6					500		
	HVEB5-8	HVE5-8	5/16	.331 8.4	.591 15.0	.531 13.5	1.382 35.1					500		

ALL LISTED