

NYLON-INSULATED LIPPED BLADE TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	9	12	17	18	30	35	50


MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

INSULATION MATERIAL: NYLON

INSULATION COLOR:

22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■

TERMINAL MATERIAL: COPPER

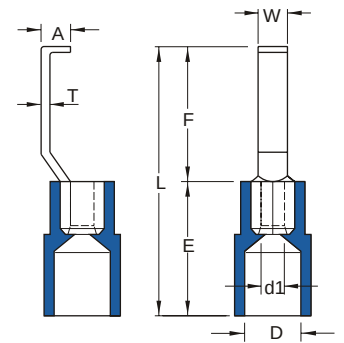

WIRE RANGE A.W.G. mm ²	ITEM NO.		DIMENSION inch mm								CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	W	F	L	E	D	d1	A	T		
22-16 A.W.G.	LBNYB1-3	LBNY1-3	.118 3.0	.685 17.4	1.110 28.2	.433 11.0	.157 4.0	.067 1.7	.083 2.1	.030 0.75	IZUMI MODEL 34 WITH DIE INDEX COLOR: RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR: RED	1000
0.5-1.5 mm ²	LBNYB1-4.6	LBNY1-4.6	.181 4.6									1000
16-14 A.W.G.	LBNYB2-3	LBNY2-3	.118 3.0	.685 17.4	1.110 28.2	.433 11.0	.177 4.5	.091 2.3	.083 2.1	.031 0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR: BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR: BLUE	1000
1.5-2.5 mm ²	LBNYB2-4.6	LBNY2-4.6	.181 4.6									1000
12-10 A.W.G.	LBNYB5-3	LBNY5-3	.118 3.0	.677 17.2	1.189 30.2	.512 13.0	.252 6.4	.134 3.4	.110 2.8	.039 1.0	IZUMI MODEL 5 WITH DIE INDEX COLOR: YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR: YELLOW	500
4-6 mm ²	LBNYB5-4.6	LBNY5-4.6	.181 4.6						.108 2.75			500

UL ALL LISTED