

## NYLON-INSULATED DOUBLE CRIMP LIPPED BLADE TERMINALS

### MAXIMUM ELECTRIC CURRENT:

| A.W.G. | 22 | 20 | 18 | 16 | 14 | 12 | 10 |
|--------|----|----|----|----|----|----|----|
| AMP.   | 9  | 12 | 17 | 18 | 30 | 35 | 50 |

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.


INSULATION MATERIAL: NYLON

INSULATION COLOR:

22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW

DOUBLE CRIMP: WITH COPPER SLEEVE ON BARREL

TERMINAL MATERIAL: COPPER

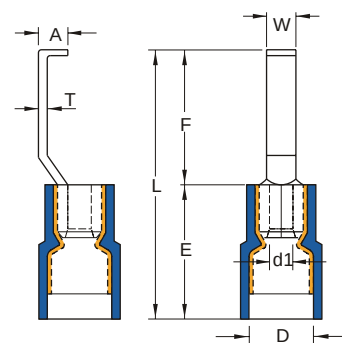

| WIRE RANGE<br>A.W.G.<br>mm <sup>2</sup>           | ITEM NO.   | DIMENSION <small>inch<br/>mm</small> |              |               |              |             |             |              |              | CRIMPING TOOL                                                                                                         | Q'TY BOX |
|---------------------------------------------------|------------|--------------------------------------|--------------|---------------|--------------|-------------|-------------|--------------|--------------|-----------------------------------------------------------------------------------------------------------------------|----------|
|                                                   |            | W                                    | F            | L             | E            | D           | d1          | A            | T            |                                                                                                                       |          |
| 22-16<br>A.W.G.<br><br>0.5-1.5<br>mm <sup>2</sup> | LBNYD1-3   | .118<br>3.0                          | .685<br>17.4 | 1.110<br>28.2 | .433<br>11.0 | .177<br>4.5 | .067<br>1.7 | .083<br>2.1  | .030<br>0.75 | IZUMI MODEL 34<br>WITH DIE INDEX<br>COLOR:RED<br><br>OR<br>K.S. MODEL<br>KST2000B<br>WITH DIE INDEX<br>COLOR:RED      | 1000     |
|                                                   | LBNYD1-4.6 | .181<br>4.6                          |              |               |              |             |             |              |              |                                                                                                                       | 1000     |
| 16-14<br>A.W.G.<br><br>1.5-2.5<br>mm <sup>2</sup> | LBNYD2-3   | .118<br>3.0                          | .685<br>17.4 | 1.110<br>28.2 | .433<br>11.0 | .205<br>5.2 | .091<br>2.3 | .083<br>2.1  | .031<br>0.8  | IZUMI MODEL 34<br>WITH DIE INDEX<br>COLOR:BLUE<br><br>OR<br>K.S. MODEL<br>KST2000B<br>WITH DIE INDEX<br>COLOR:BLUE    | 1000     |
|                                                   | LBNYD2-4.6 | .181<br>4.6                          |              |               |              |             |             |              |              |                                                                                                                       | 1000     |
| 12-10<br>A.W.G.<br><br>4-6 mm <sup>2</sup>        | LBNYD5-3   | .118<br>3.0                          | .677<br>17.2 | 1.189<br>30.2 | .512<br>13.0 | .276<br>7.0 | .134<br>3.4 | .110<br>2.8  | .039<br>1.0  | IZUMI MODEL 5<br>WITH DIE INDEX<br>COLOR:YELLOW<br><br>OR<br>K.S. MODEL<br>KST2000B<br>WITH DIE INDEX<br>COLOR:YELLOW | 500      |
|                                                   | LBNYD5-4.6 | .181<br>4.6                          |              |               |              |             |             | .108<br>2.75 |              |                                                                                                                       | 500      |

UL cUL ALL LISTED