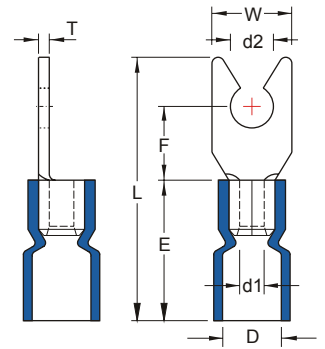


# VINYL-INSULATED (EASY ENTRY) LOCKING SPADE TERMINALS

**MAXIMUM ELECTRIC CURRENT:**

|        |    |    |    |    |    |    |    |
|--------|----|----|----|----|----|----|----|
| A.W.G. | 22 | 20 | 18 | 16 | 14 | 12 | 10 |
| AMP.   | 9  | 12 | 17 | 18 | 30 | 35 | 50 |

**MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.**
**INSULATION MATERIAL: VINYL**
**INSULATION COLOR:**

 22-16 A.W.G.: RED ■    16-14 A.W.G.: BLUE ■    12-10 A.W.G.: YELLOW ■
**TERMINAL MATERIAL: COPPER**


| WIRE RANGE<br>A.W.G.<br>mm <sup>2</sup>           | ITEM NO.    |             | STUD SIZE |             | DIMENSION <small>inch mm</small> |             |               |              |             |             |              | CRIMPING TOOL                                                                                                                  | Q'TY BOX |
|---------------------------------------------------|-------------|-------------|-----------|-------------|----------------------------------|-------------|---------------|--------------|-------------|-------------|--------------|--------------------------------------------------------------------------------------------------------------------------------|----------|
|                                                   | BRAZED SEAM | BUTTED SEAM |           | d2          | W                                | F           | L             | E            | D           | d1          | T            |                                                                                                                                |          |
| 22-16<br>A.W.G.<br><br>0.5-1.5<br>mm <sup>2</sup> | LSVEB1-3.2  | LSVE1-3.2   | #4        | .126<br>3.2 | .252<br>6.4                      | .256<br>6.5 | .874<br>22.2  | .441<br>11.2 | .157<br>4.0 | .067<br>1.7 | .030<br>0.75 | IZUMI MODEL 34<br>WITH DIE INDEX<br>COLOR:RED<br><br>OR<br>K.S. MODEL<br>KST2000A<br>HRI-126J<br>WITH DIE INDEX<br>COLOR:RED   | 1000     |
|                                                   | LSVEB1-3.7  | LSVE1-3.7   | #6        | .146<br>3.7 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBS1-4   | LSVES1-4    | #8        | .169<br>4.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBL1-4   | LSVEL1-4    | #8        | .169<br>4.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBS1-5   | LSVES1-5    | #10       | .209<br>5.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBL1-5   | LSVEL1-5    | #10       | .209<br>5.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
| 16-14<br>A.W.G.<br><br>1.5-2.5<br>mm <sup>2</sup> | LSVEB2-3.2  | LSVE2-3.2   | #6        | .146<br>3.7 | .236<br>6.0                      | .256<br>6.5 | .886<br>22.5  | .453<br>11.5 | .177<br>4.5 | .091<br>2.3 | .031<br>0.8  | IZUMI MODEL 34<br>WITH DIE INDEX<br>COLOR:BLUE<br><br>OR<br>K.S. MODEL<br>KST2000A<br>HRI-126J<br>WITH DIE INDEX<br>COLOR:BLUE | 1000     |
|                                                   | LSVEB2-3.7  | LSVE2-3.7   | #6        | .146<br>3.7 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBL2-3.7 | LSVEL2-3.7  | #6        | .146<br>3.7 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEB2-4    | LSVE2-4     | #8        | .169<br>4.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBL2-4   | LSVEL2-4    | #8        | .169<br>4.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBS2-5   | LSVES2-5    | #10       | .209<br>5.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEBL2-5   | LSVEL2-5    | #10       | .209<br>5.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
|                                                   | LSVEB2-6    | LSVE2-6     | 1/4       | .252<br>6.4 |                                  |             |               |              |             |             |              |                                                                                                                                | 1000     |
| 12-10<br>A.W.G.<br><br>4-6<br>mm <sup>2</sup>     | LSVEBS5-3.7 | LSVES5-3.7  | #6        | .146<br>3.7 | .307<br>7.8                      | .276<br>7.0 | 1.035<br>26.3 | .555<br>14.1 | .248<br>6.3 | .134<br>3.4 | .039<br>1.0  | IZUMI MODEL 5<br>WITH DIE INDEX<br>COLOR:YELLOW<br>OR<br>K.S. MODEL<br>KST2000A<br>HRI-126J<br>WITH DIE INDEX<br>COLOR:YELLOW  | 500      |
|                                                   | LSVEB5-3.7  | LSVE5-3.7   | #6        | .146<br>3.7 |                                  |             |               |              |             |             |              |                                                                                                                                | 500      |
|                                                   | LSVEB5-4    | LSVE5-4     | #8        | .169<br>4.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 500      |
|                                                   | LSVEB5-5    | LSVE5-5     | #10       | .209<br>5.3 |                                  |             |               |              |             |             |              |                                                                                                                                | 500      |
|                                                   | LSVEB5-6    | LSVE5-6     | 1/4       | .252<br>6.4 |                                  |             |               |              |             |             |              |                                                                                                                                | 500      |

(UL) c(UL) ALL LISTED