

NYLON-INSULATED BULLET DISCONNECTORS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.


INSULATION MATERIAL: NYLON TERMINAL MATERIAL: BRASS

INSULATION COLOR:

22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■

TERMINAL BARREL I.D.:

22-16 A.W.G.: C=1.7mm 16-14 A.W.G.: C=2.3mm 12-10 A.W.G.: C=3.4mm

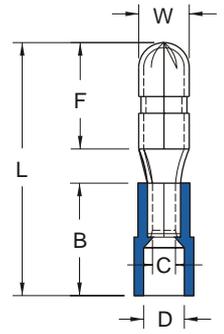

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION <small>inch mm</small>						CRIMPING TOOL	Q'TY BOX	
		W	F	L	B	D	T			
22-16 A.W.G. 0.5-1.5 mm ²	MPNY1-156	.157 4.0	.335 8.5	.866 22.0	.433 11.0	.157 4.0	.016 0.4	K.S.MODEL KST2000C WITH DIE INDEX COLOR:RED	1000	
	MPNYL1-156		.413 10.5	.945 24.0					1000	
	MPNY1-180	.177 4.5	.335 8.5	.866 22.0					1000	
	MPNYL1-180		.425 10.8	.953 24.2					1000	
16-14 A.W.G. 1.5-2.5 mm ²	MPNY2-156	.157 4.0	.335 8.5	.866 22.0	.433 11.0	.177 4.5	.016 0.4		K.S.MODEL KST2000C WITH DIE INDEX COLOR:BLUE	1000
	MPNYL2-156		.413 10.5	.945 24.0						1000
	MPNY2-180	.177 4.5	.354 9.0	.874 22.2						1000
	MPNYL2-180		.425 10.8	.933 23.7						1000
	MPNY2-195	.197 5.0	.335 8.5	.866 22.0				1000		
12-10 A.W.G. 4-6 mm ²	MPNY5-195	.197 5.0	.335 8.5	.925 23.5	.512 13.0	.248 6.3	.016 0.4	K.S.MODEL KST2000C WITH DIE INDEX COLOR:YELLOW	500	

ALL LISTED

