

NYLON-INSULATED DOUBLE CRIMP BULLET DISCONNECTORS


MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: NYLON TERMINAL MATERIAL: BRASS
INSULATION COLOR:

 22-16 A.W.G.: RED ■ 16-14 A.W.G.: BLUE ■ 12-10 A.W.G.: YELLOW ■
DOUBLE CRIMP: WITH COPPER SLEEVE ON BARREL
TERMINAL BARREL I.D.:

22-16 A.W.G.: C=1.7mm 16-14 A.W.G.: C=2.3mm 12-10 A.W.G.: C=3.4mm

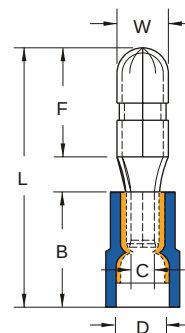

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION ^{inch} mm						CRIMPING TOOL	Q'TY BOX
		W	F	L	B	D	T		
22-16 A.W.G. 0.5-1.5 mm ²	MPNYD1-156	.157 4.0	.335 8.5	.866 22.0	.433 11.0	.157 4.0	.016 0.4	K.S. MODEL 34 OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:RED	1000
	MPNYDL1-156		.413 10.5	.945 24.0					1000
	MPNYD1-180	.177 4.5	.335 8.5	.866 22.0					1000
	MPNYDL1-180		.425 10.8	.953 24.2					1000
16-14 A.W.G. 1.5-2.5 mm ²	MPNYD2-156	.157 4.0	.335 8.5	.866 22.0	.433 11.0	.197 5.0	.016 0.4	K.S. MODEL 34 OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:BLUE	1000
	MPNYDL2-156		.413 10.5	.945 24.0					1000
	MPNYD2-180	.177 4.5	.335 8.5	.866 22.0					1000
	MPNYDL2-180		.425 10.8	.953 24.2					1000
	MPNYD2-195	.197 5.0	.335 8.5	.866 22.0					1000
12-10 A.W.G. 4-6 mm ²	MPNYD5-195	.197 5.0	.335 8.5	.925 23.5	.512 13.0	.256 6.5	.016 0.4	K.S. MODEL 5 OR K.S. MODEL KST2000A WITH DIE INDEX COLOR:YELLOW	500