


# VINYL-INSULATED PARALLEL CONNECTORS

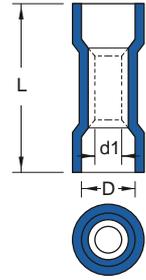

**MAXIMUM ELECTRIC CURRENT:**

A.W.G.	22	20	18	16	14	12	10	8	6	4	2
AMP.	9	12	17	18	30	35	50	70	95	125	170

**MAXIMUM ELECTRICAL RATING: 75°C 600 VOLTS MAX.**

**CONNECTOR MATERIAL: COPPER**

**INSULATION COLOR:**

22-16 A.W.G.: RED ■      16-14 A.W.G.: BLUE ■      12-10 A.W.G.: YELLOW ■

8 A.W.G.: RED ■      6 A.W.G.: BLUE ■      4 A.W.G.: YELLOW ■      2 A.W.G.: RED ■

**INSULATION MATERIAL: VINYL**

WIRE RANGE A.W.G. mm <sup>2</sup>	ITEM NO.	DIMENSION <small>inch mm</small>			MATERIAL	CRIMPING TOOL	Q'TY BOX
		L	D	d1			
22-16 A.W.G. 0.5-1.5 mm <sup>2</sup>	PVT1	.650 16.5	.157 4.0	.067 1.7	COPPER TUBULAR	K.S. MODEL <b>KST2000A</b> HRI-126J WITH DIE INDEX COLOR:RED	1000
16-14 A.W.G. 1.5-2.5 mm <sup>2</sup>	PVT2	.650 16.5	.177 4.5	.091 2.3	COPPER TUBULAR	K.S. MODEL <b>KST2000A</b> HRI-126J WITH DIE INDEX COLOR:BLUE	1000
12-10 A.W.G. 4-6 mm <sup>2</sup>	PVT5	.795 20.2	.248 6.3	.134 3.4	COPPER TUBULAR	K.S. MODEL <b>KST2000A</b> HRI-126J WITH DIE INDEX COLOR:YELLOW	500
8 8 A.W.G. mm <sup>2</sup>	PVT8	.945 24.0	.335 8.5	.177 4.5	COPPER TUBULAR	K.S. MODEL <b>KST-HDC38A</b> WITH DIE INDEX INS(AWG) NO:8	200
6 14 A.W.G. mm <sup>2</sup>	PVT14	1.181 30.0	.413 10.5	.232 5.9	COPPER TUBULAR	K.S. MODEL <b>KST-HDC38A</b> WITH DIE INDEX INS(AWG) NO:14	100
4 22 A.W.G. mm <sup>2</sup>	PVT22	1.457 37.0	.488 12.4	.307 7.8	COPPER TUBULAR	K.S. MODEL <b>KST-HDC38A</b> WITH DIE INDEX INS(AWG) NO:22	100
2 38 A.W.G. mm <sup>2</sup>	PVT38	1.496 39.5	.610 15.5	.374 9.5	COPPER TUBULAR	K.S. MODEL <b>KST-HDC38A</b> WITH DIE INDEX INS(AWG) NO:38	50

**UL** US ALL LISTED