


DIMENSIONS: mm

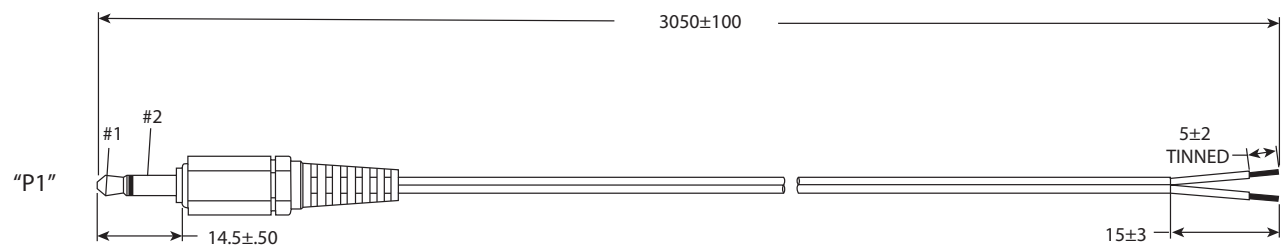

CONNECTION	
P1	WIRE COLOR
1	BLACK
2	BLACK/WHITE LINE

Specifications:

- Operating Temperature: -10°C ~ +80°C
- Insulation Resistance: DC/250V, 10MΩ Min.
- Withstand Voltage: AC/250V 2mA For One Minute.
- Continuity Resistance: 3Ω
- Continuity Test: 100%
- Tensile Strength: Overmold to cable jacket shall withstand 3kgf pull min. for one minute.
- 24 AWG Standard wire.

Notes:

- RoHS Compliant