


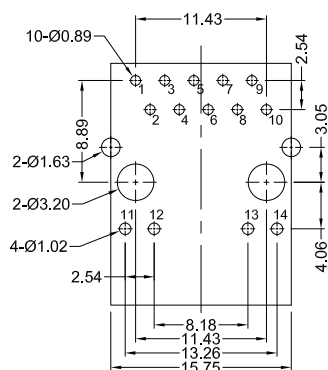


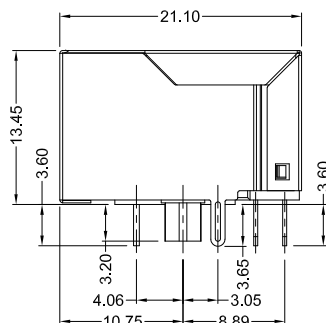

Insertion Loss (dB Max)	Return Loss (dB Min)		Cross Talk (dB Min)	CMR (dB Min)	OCL (uH Min)
1~125 MHz	1~40 MHz	40~200 MHz	1~125 MHz	30~200 MHz	@100 KHz & 0.1 V
-1.0	-20	-20+15LOG ₁₀ (f/40MHz)	-30	-30	180

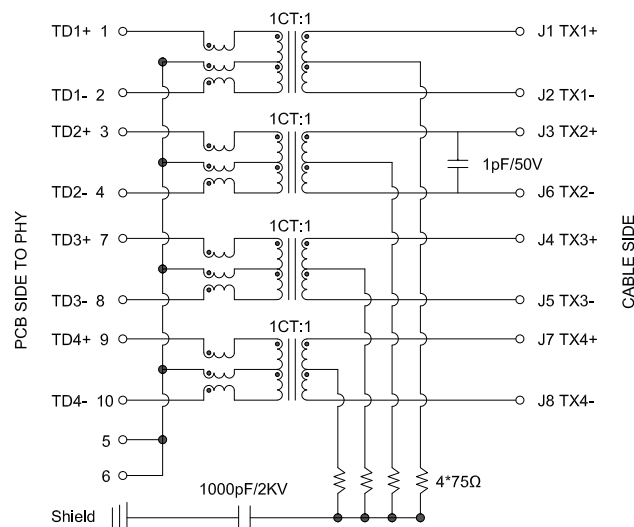

Standard LED Color	LED Wavelength	Foward(A)	Foward(V)
Green	568nm	20mA	1.85-2.45V
Yellow	585nm	20mA	1.7-2.2V

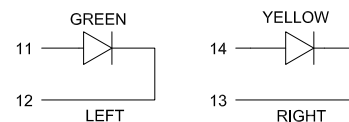

Durability Rating:
750 Mating Cycles Min.
Operating Temperature:
-40°C to +85°C

G15LX-110S-2.5G-G/Y-15

Tab Down, Shielded, LEDs



X.X $\pm$ 0.30
X.XX $\pm$ 0.25
Unless Stated
Otherwise

RoHS COMPLIANT

