
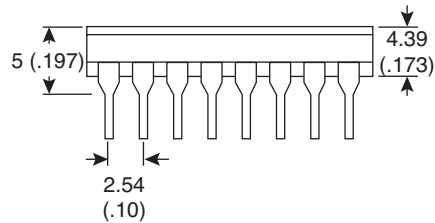
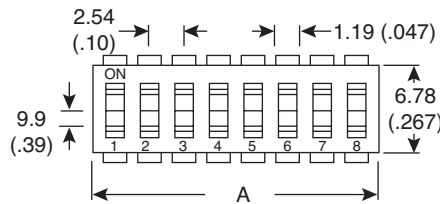
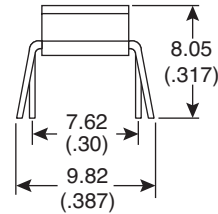


Dimensions: mm (In.)

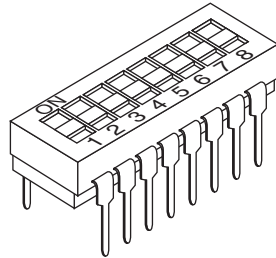

Mouser Stock No.	Position	Dimension "A" (In.)
106-1222-EV	2	.198
106-1224-EV	4	.398
106-1228-EV	8	.881

Electrical Specifications:

- Electrical life: 2,000 operations min.
- Rating: Non-switching: 100mA/50VDC
Switching rating: 25mA / 24VDC
- Contact resistance: 30mΩ max. initial
100mΩ max. @ end of life
- Insulation resistance: 100M min. @ end of life
- Dielectric strength: 500VDC for 1 minute
- Capacitance: 5pF max. between adjacent closed switch.
- Frequency: 1MHz

Mechanical Specifications:

- Type: SPST
- Mechanical life: 5,000 operations min.
- Operation force: <800g
- Stroke: 1.0mm
- Operating & storage temperature: -40°C~ +85°C

Note:

- RoHS Compliant and Process Compatible with 260° solder

Ultra-Low Profile DIP Switches
106-1222-EV, 106-1224-EV, 106-1228-EV

