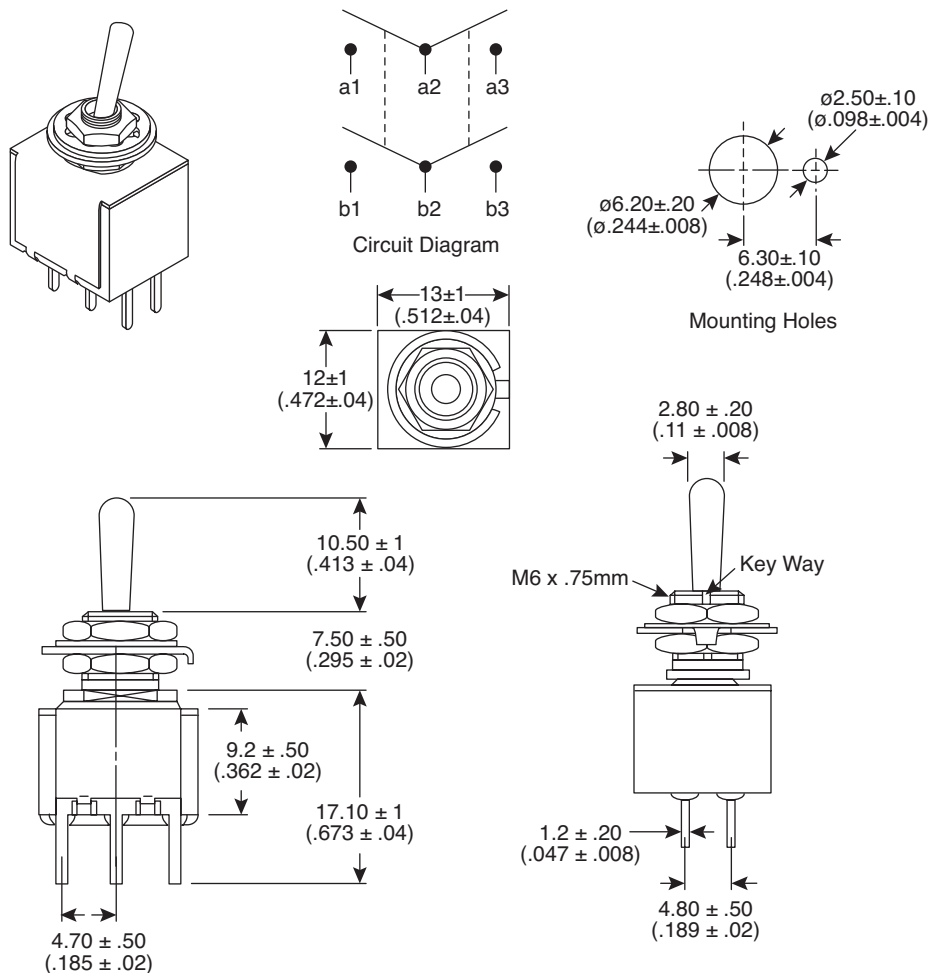


DIMENSIONS: mm (in.)

**Electrical Specifications:**

- Rating: 6A/125VAC, 3A/250VAC
- Contact resistance: 50Ω max.
- Insulation resistance: 100MΩ min. @500VDC
- Dielectric strength: 1000VAC for 1 minute
- Electrical life: 10,000 cycles

Mechanical Specifications:

- Mechanical life: 100,000 cycles
- Operating temperature: -20°~+65°C
- Circuit: DPDT On-Off-On

Note:

- RoHS Complaint by Exemption

Miniature Toggle Switch
1055-TA1365B-EVX

Mountain
Switch