
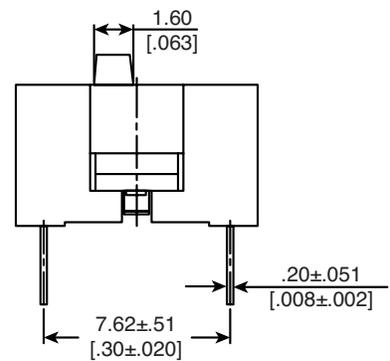
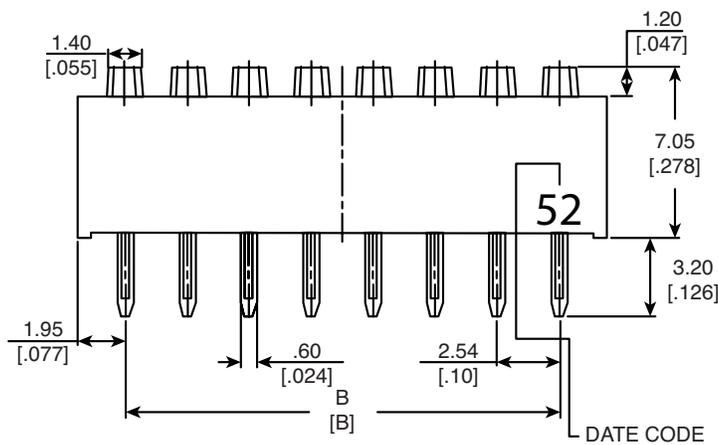
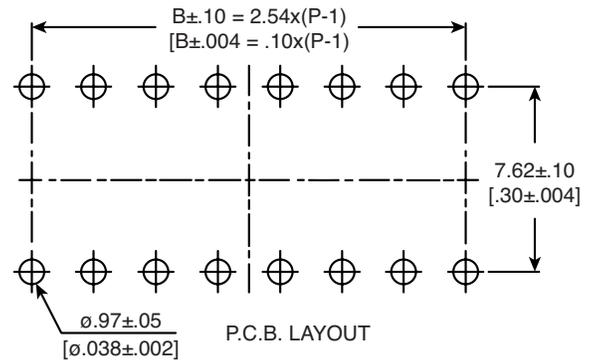


Dimensions: mm (in.)

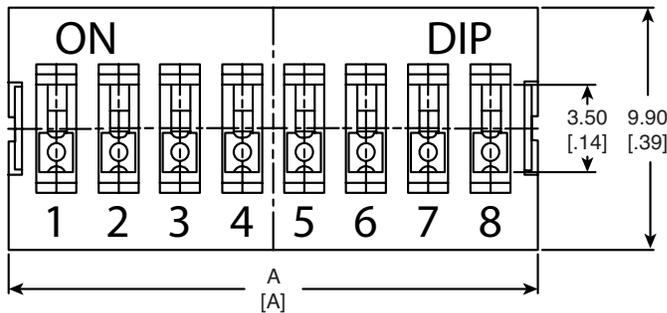

Mountain Switch Part No.	No. of Positions	Dim. A	Dim. B
106-SDN02-EV	2	6.44 [.254]	2.54 [.100]
106-SDN04-EV	4	11.52 [.454]	7.62 [.300]
106-SDN06-EV	6	16.60 [.654]	12.70 [.500]
106-SDN08-EV	8	21.68 [.854]	17.78 [.700]

Mechanical Specifications:

- Operating Temperature Range: -40°C ~ +85°C
- Storage Temperature Range: -40°C ~ +85°C

Soldering Process:

- Manual Soldering:
 - Soldering Temperature: Max. 350°C
 - Continuous Soldering Time: Max. 5 seconds

Electrical Specifications:

- Rating: Switching: 25mA/24VDC
Non-Switching: 100mA/50VDC
- Contact Resistance: 50mΩ Max. (initial)
- Insulation Resistance: 100MΩ Min.
- Dielectric Strength: 500VAC (50Hz or 60Hz) for 1 minute

Note:

- RoHS Compliant

DIP Switches

106-SDN02-EV, 106-SDN04-EV,
106-SDN06-EV, 106-SDN08-EV

