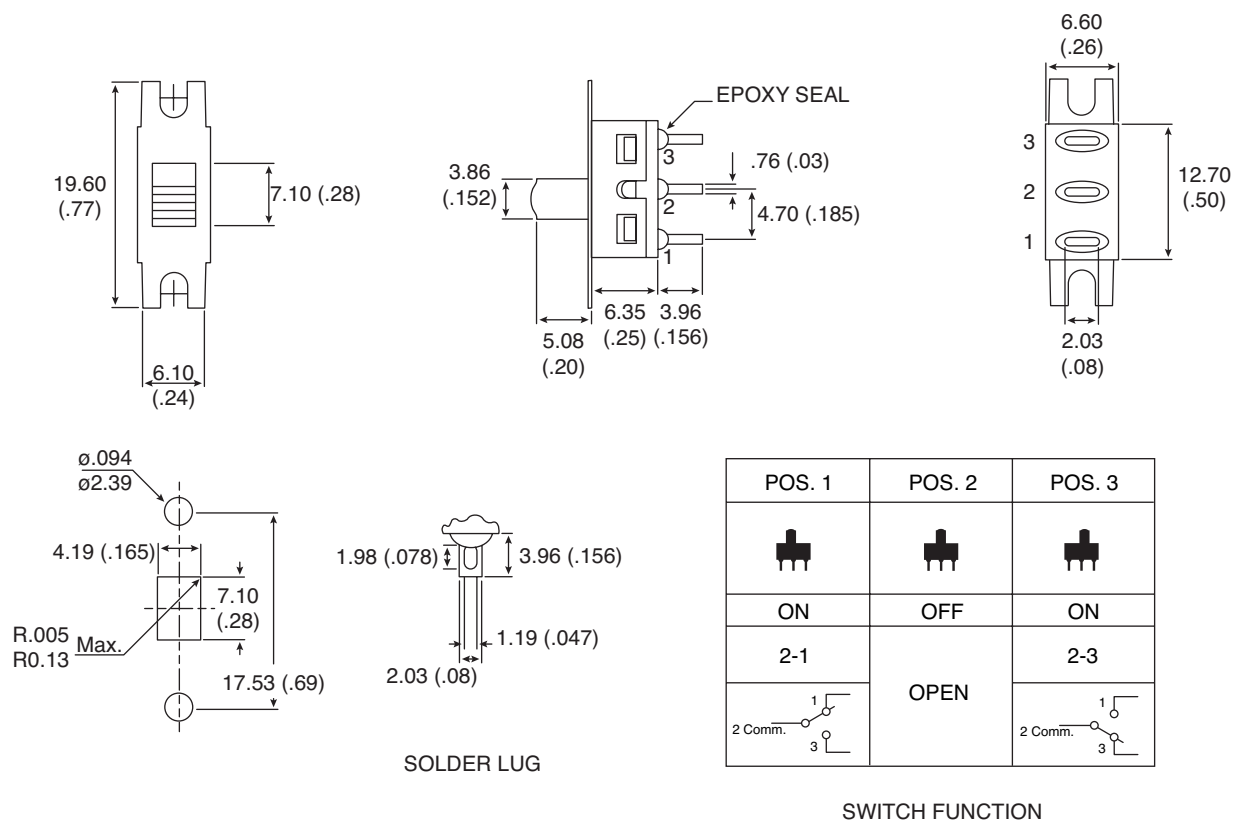


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 2A/250VAC; 5A/120VAC or 28VDC
- Contact Resistance: 10m Ω Max. initial @2-4VDC 100mA
- Insulation Resistance: 1,000M Ω Min.
- Dielectric Strength: 1,000 V RMS@ sea level

Mechanical Specifications:

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Materials:

- Case: Dially Phthalate (DAP)
- Actuator: Nylon, Black std.
- Housing: Stainless Steel
- Contact: Silver or Gold Plated
- Terminal Seal: Epoxy

Note:

- RoHS compliant

Slide Switch
103-5010-EV

Mountain
Switch