



Dimensions: mm (In.)

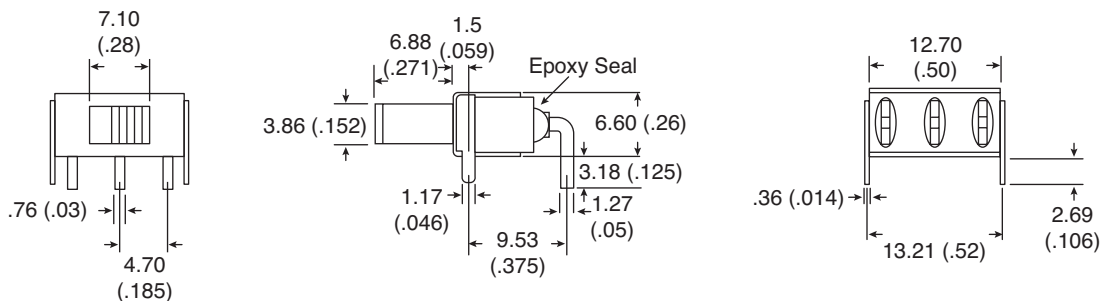

POS. 1	POS. 2	POS. 3
ON	OFF	ON
2-1	OPEN	2-3

SWITCH FUNCTION

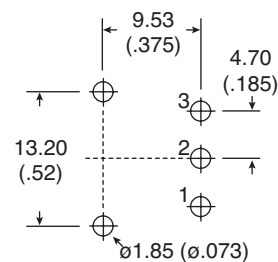

P.C. MOUNTING

Electrical Specifications:

- Rating: 2A/250VAC, 5A/120VAC or 28VDC
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS @ sea level

Materials:

- Case: Dially phthalate (DAP)
- Actuator: Nylon, Black Std.
- Housing: Stainless Steel
- Contact: Silver or Gold Plated
- Terminal Seal: Epoxy

Mechanical Specifications:

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Note:

- RoHS compliant

Slide Switch
103-5011-EV

Mountain
Switch