



Dimensions: mm (In.)

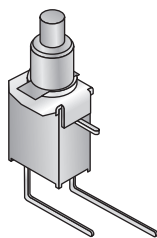

POS. 1	POS. 2
	
OFF	MOM
OPEN	1-3
	

SWITCH FUNCTION

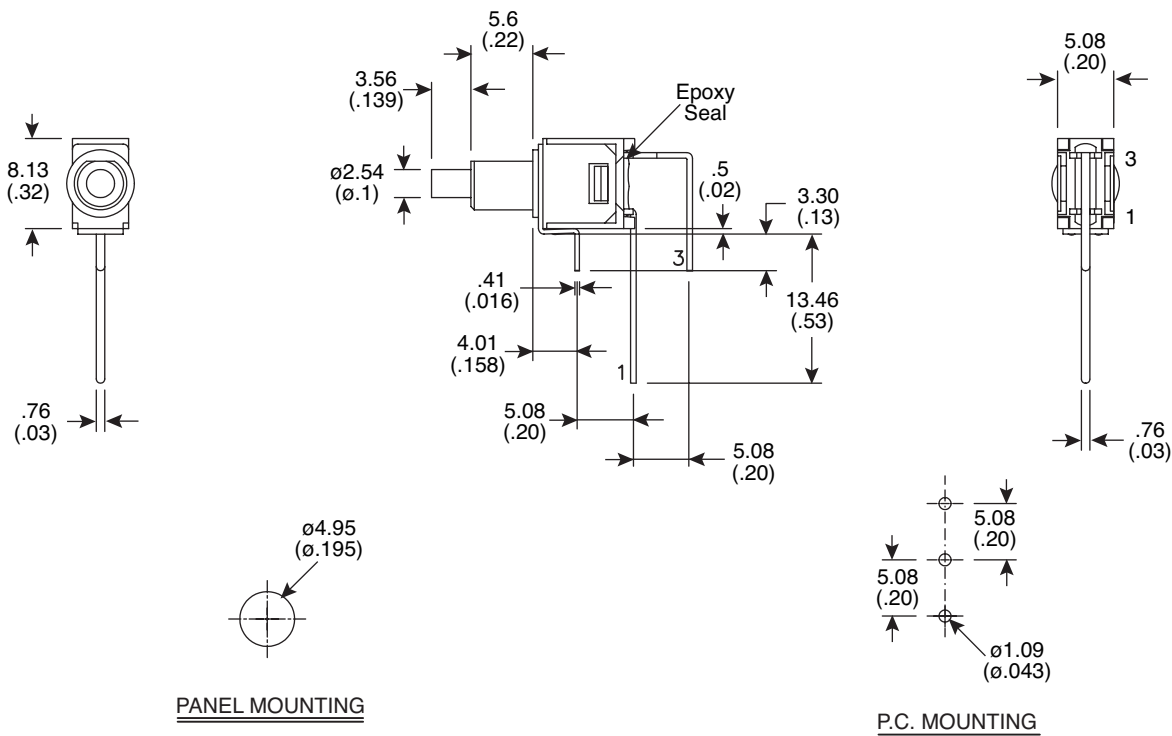

Electrical Specifications:

- Rating: 1A/250VAC, 3A/120VAC or 28 VDC
- Contact Resistance: 20mΩmax. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩmin.
- Dielectric Strength: 1,000 V RMS@ sea level

Mechanical Specifications:

- Mechanical Life: 60,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Note:

- RoHS compliant by exemption

Materials:

- Case: Diallyl phthalate (DAP)
- Plunger: Thermoplastic Polyester-black
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Contact: Silver or Gold plated
- Terminal: Brass, Silver plated
- Terminal Support: Brass, tin plated

Snap-Acting Pushbutton Switch
107-3025-EVX

Mountain
Switch