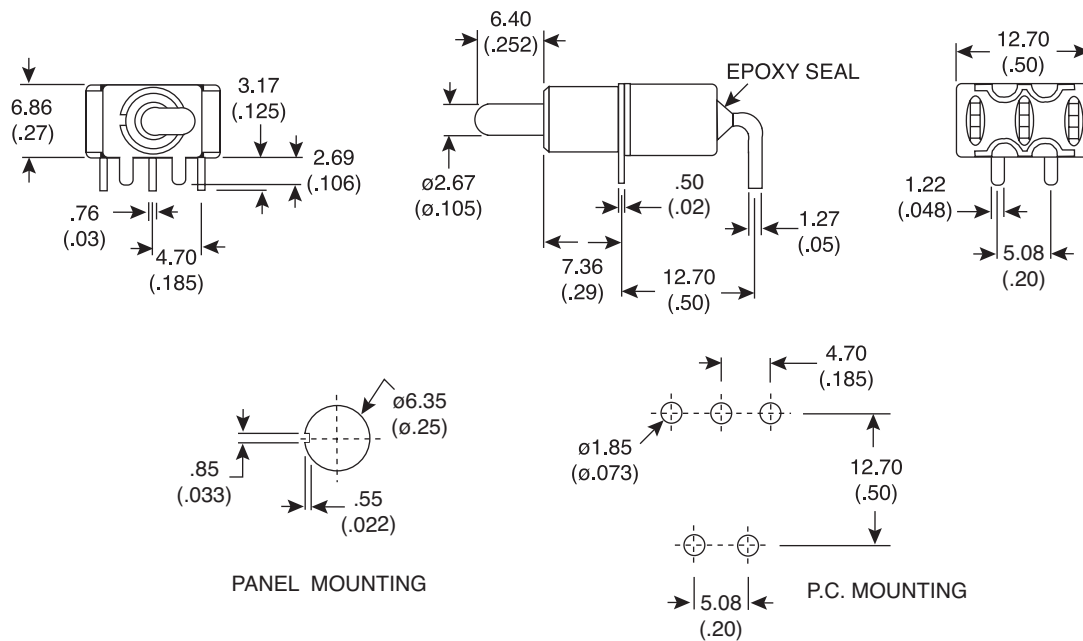


DIMENSIONS: mm (in.)

POS.1	POS.2	POS.3
ON	OFF	ON
2-3	OPEN	2-1

SWITCH FUNCTION

Mechanical Specifications:

- Operating Temperature: -30° C to +85° C.

Electrical Specifications:

- Electrical Life: 40,000 make-and-break cycles at full load
- Contact Resistance: 10m Ω max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M Ω min.
- Rating: 2A/250 VAC, 5A/120 VAC or 28 VDC
- Dielectric Strength: 1,000 V RMS@ sea level

Materials:

- Case: Diallyl phthalate (DAP)
- Actuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Terminal/Contact: Silver or Gold plated.

Note:

- RoHS Compliant by Exemption

Toggle Switch
108-1MS3T2B4M6QE-EVX

**Mountain
Switch**