


2ODD8-010M

MM (Beige) 62.5/125 ODVA to Duplex LCUPC, OSP Jacket 10 Meter

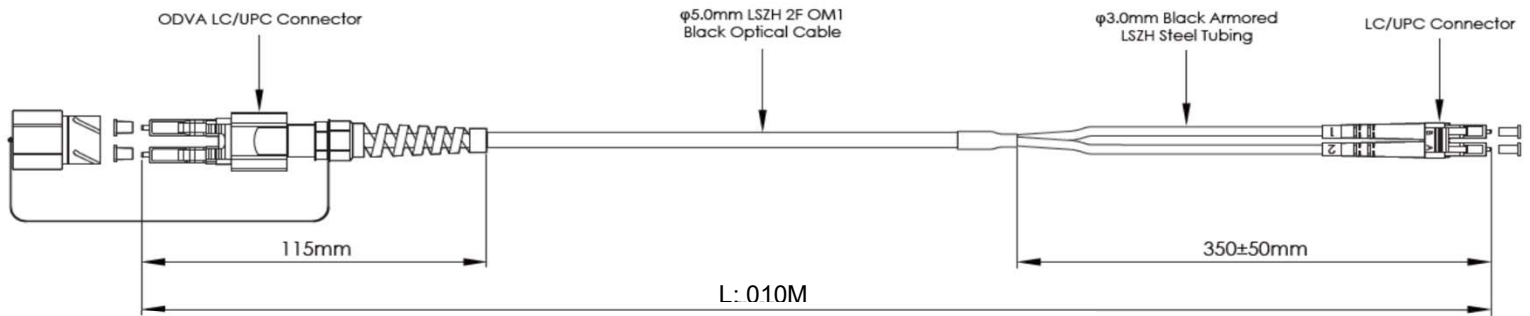

FIBER CONNECTIVITY			
ODVA CONN		LC CONN	
A	→	→	B
B	→	→	A



Specifications

Product Brand	MEGLADON MANUFACTURING GROUP LTD.
Application Type	INDOOR/OUTDOOR, FIBER-TO-THE-ANTENNA (FTTA) CABLE ASSEMBLY
Connector Types	(1) ODVA LC/UPC (1) Duplex LC/UPC
Jacketing Material	5.0mm LSZH(UV), Black
Glass Mode	OM1-62.5/125μm
Fiber Count	2F
Length (Meters Feet)	10 Meter

Color, Boot A	WHITE
Color, Boot B	WHITE
Color, connector A	BEIGE
Color, Connector B	BEIGE
Environmental Space	INDOOR/OUTDOOR, FIBER JUMPER CABLE ASSEMBLY
Operation Temperature (deg. C)	-40 °C to 75 °C -40 °F to 167 °F
Storage Temperature (deg. C)	-40 °C to 75 °C -40 °F to 167 °F

Insertion Loss, typical note	Insertion loss is measured at 850nm
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.3 dB
Return Loss, minimum, connector A	30 dB
Return Loss, minimum, connector B	30 dB

RoHS Compliance	Free of hazardous substances according to RoHS 2011/65/EU
-----------------	---