


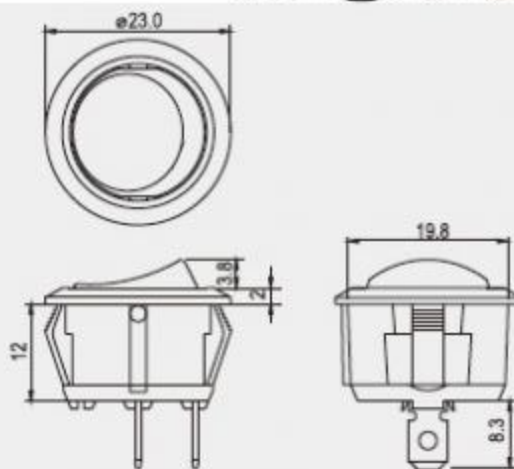

Rating

16A 125V AC
10A 250V AC

Contact resistance

50mΩ Max


Insulation resistance

DC 500V 100MΩ Min

Dielectric strength

AC 1500V 1 minute

Cut-out

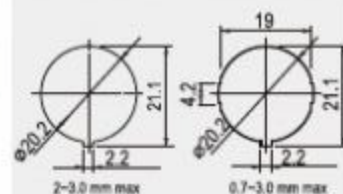

0.7~3.0 mm max

FEATURES

- * MATERIAL: Frame is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- * Snap-in mounting, easy to install switch into panel.
- * Watertight cover is optional.
- * The dimension of frame is 12mm, for longer one, please refer to page 1-53~1-54 item no. R13-112.



Ordering number instruction

R13-208

FUNCTION

TERMINAL

Different button (按鈕不同)



0 2 .187" SQ

0 9 PC

A/C/D/E/F/G/H/I


1 2 SO

A/C/D/E/F/G/H/I


Illuminated / Different button (帶燈/按鈕不同)



Momentary / Illuminated / Different button (彈回/帶燈/按鈕不同)

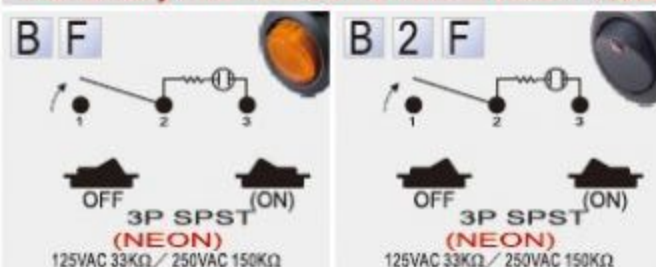

Different position (動作特性不同)

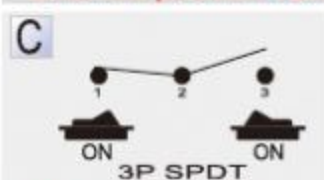

Momentary (彈回)

