


R1-34

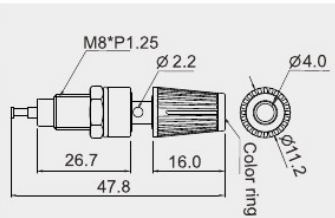

0.7~7.0mm

10A

DC500V 100MΩ

AC 1500V 1 minute

-20°C~+80°C

FEATURES:

- Material:
Insulation: nylon(UL flame: 94V-2).
Metal: nickel plated brass.
- $\varnothing 4.0\text{mm}$ (0.160") banana socket with $\varnothing 2.2\text{mm}$ (0.087") cross hole and $\varnothing 4.0\text{mm}$ (.160") cross hole.

CUT-OUT

