


R13-135

Screw Type

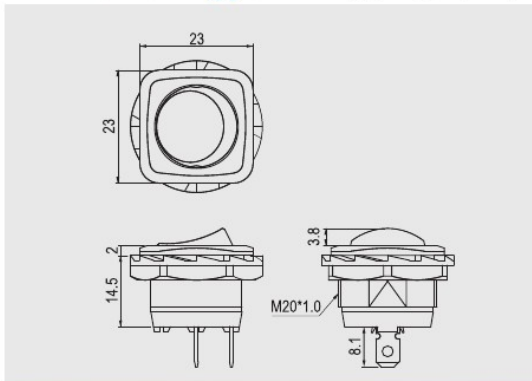

Rating
16A 125V AC 10A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

FEATURES

- * MATERIAL: Frame is nylon with glass fiber (UL flame: 94V-2). Terminals are silver plated brass.
- * Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- * Mounted by nut.



Ordering number instruction

R13-135 -

FUNCTION				TERMINAL
Different button (按鈕不同)				0 2 .187" SQ 0 9 PC A/C/D/E/F/G/H/I 1 2 SO A/C/D/E/F/G/H/I/L
Illuminated/ Different button (帶燈/ 按鈕不同)				
A 2P SPST	A 2 2P SPST	A P 2P SPST		
B 3P SPST (NEON) 125VAC 33KΩ / 250VAC 150KΩ	B 2 3P SPST (W/Lens) (NEON) 125VAC 33KΩ / 250VAC 150KΩ	B 9 3P SPST (W/O Lens) (LED) 125VAC 33KΩ / 250VAC 150KΩ	B P 3P SPST (NEON) 125VAC 33KΩ / 250VAC 150KΩ	
Different position / Different button (動作特性不同/ 按鈕不同)				
C 3P SPDT	C P 3P SPDT	D 3P SPDT	D P 3P SPDT	
Momentary (彈回)				
E 2P SPST	F 2P SPST	G 3P SPDT	H 3P SPDT	
I 3P SPDT				
Independent circuit (獨立迴路)				
L 4P SPST (LED)	L P 4P SPST (LED)	L F 4P SPST (LED)		