

R13-208

Shorter Frame Than R13-112

CNS CQC D

15 10


11037-4401

10037-4401

US

US

TUV

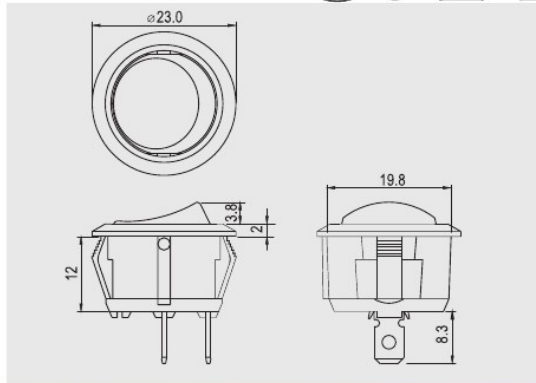

Rating
16A 125V AC 10A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

FEATURES

- * MATERIAL: Frame is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- * Snap-in mounting, easy to install switch into panel.
- * Watertight cover is optional.
- * The dimension of frame is 12mm, for longer one, please refer to page 1-53~1-54 item no. R13-112.



Ordering number instruction

R13-208 -

FUNCTION				TERMINAL	
Different button (按鈕不同)				0 2	.187" SQ
				0 9	PC A/C/D/E/F/G/H/I
				1 2	SO A/C/D/E/F/G/H/I
Illuminated / Different button (帶燈/按鈕不同)					
Momentary / Illuminated / Different button (彈回/帶燈/按鈕不同)					
Different position (動作特性不同)					
Momentary (彈回)					