


R13-240

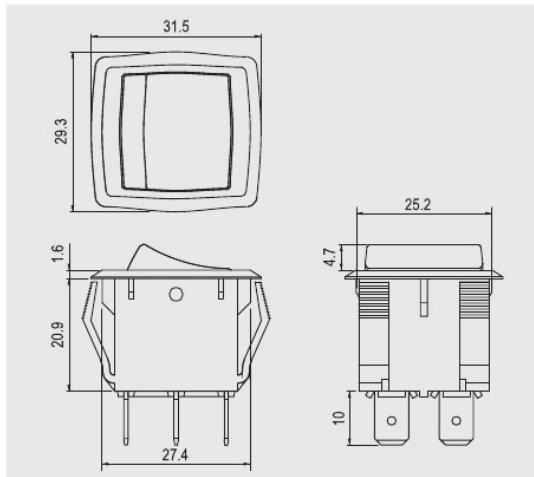

Rating
16A 125V AC 1/3HP 10A 250V AC 1/2HP
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out

	X	Y
0.75-3.0	27.6-0.1	25.4+0.1
3.0-5.0	28.0-0.1	25.4+0.1
5.0-6.3	28.6-0.1	25.4+0.1

FEATURES

- * MATERIAL: Frame is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- * Snap-in mounting, easy to install switch into panel.

R13-240 -

