


R13-405

Screw type

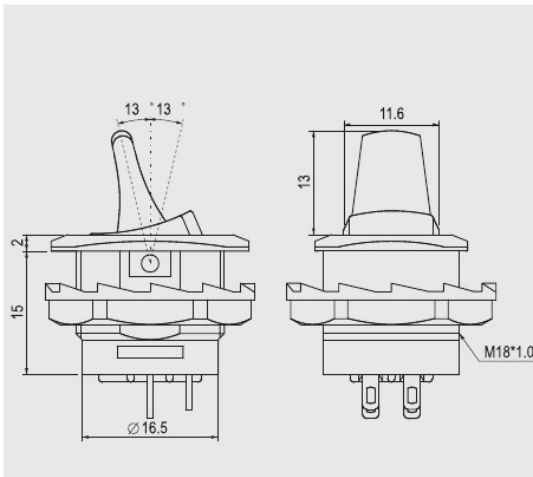

Rating
10A 125V AC 6A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

FEATURES

- * MATERIAL: Frame is nylon (UL flame: 94V-2). Base is PBT (UL flame: 94V-0). Terminals are silver plated brass.
- * LED indicator on the top of lever. (AL, CL, DL type only). LED available with red, amber, green, blue and white colors.

R13-405

FUNCTION		TERMINAL	LEVER
A OFF 4P DPST	AL OFF 4P SPST (LED)	0 5 SO	A/C/D/G
C ON 6P DPDT	CL ON 5P SPDT (LED)		AL/CL/DL
D ON 6P DPDT	DL ON 5P SPDT (LED)		
G (ON) 6P DPDT	* () =momentary		

