



R13-523

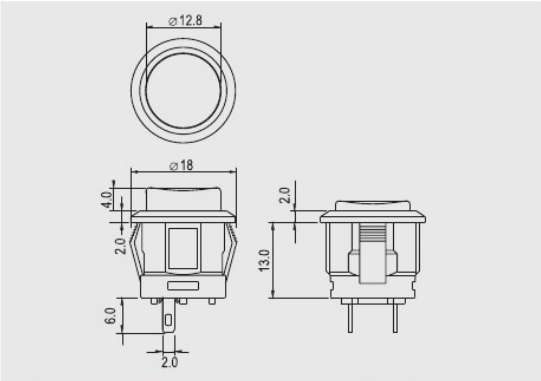

| Rating                     |
|----------------------------|
| 3A 125V AC<br>1.5A 250V AC |
| Contact resistance         |
| 50mΩ Max                   |
| Insulation resistance      |
| DC 500V 100MΩ Min          |
| Dielectric strength        |
| AC 1500V 1 minute          |
| Cut-out                    |

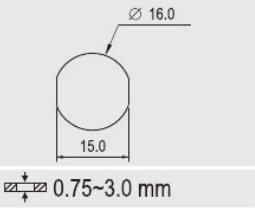

FEATURES

- \* MATERIAL: Frame is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- \* Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- \* Snap-in mounting, easy to install switch into panel.
- \* Same mounting hole as R13-555, but in different shape of bezel and button.

R13-523     -    

| FUNCTION                         |                                | BUTTON                                                 | TERMINAL                                                          |
|----------------------------------|--------------------------------|--------------------------------------------------------|-------------------------------------------------------------------|
| <b>A</b><br><br>OFF 2P SPST (ON) | <b>B</b><br><br>OFF 2P SPST ON | <input checked="" type="checkbox"/> W/O LED            | <span style="border: 1px solid red; padding: 2px;">0 5  SO</span> |
|                                  |                                | <input type="checkbox"/> With LED<br>(LED INDEPENDENT) |                                                                   |

\* ( ) =momentary