



R13-523

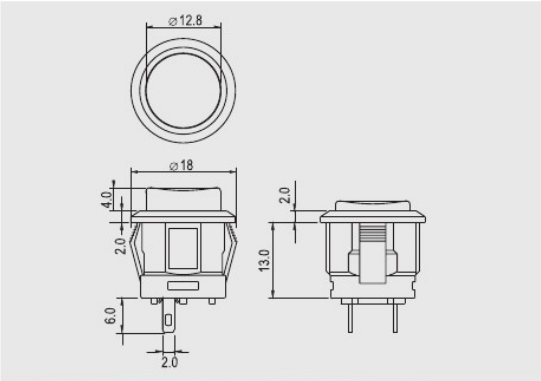

Rating
3A 125V AC 1.5A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

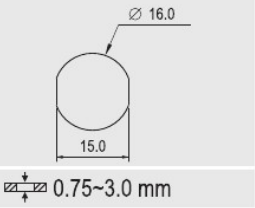

FEATURES

- * MATERIAL: Frame is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- * Snap-in mounting, easy to install switch into panel.
- * Same mounting hole as R13-555, but in different shape of bezel and button.

R13-523 -

FUNCTION		BUTTON	TERMINAL
A OFF 2P SPST (ON)	B OFF 2P SPST ON	☒ W/O LED	0 5 SO
		☐ With LED (LED INDEPENDENT)	

* () =momentary