


R13-57

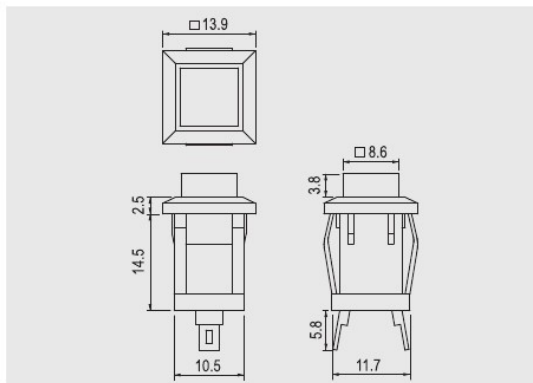

Rating
1A 125V AC 0.5A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out
 3 mm max

FEATURES

- * MATERIAL: Frame and Actuator is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Snap in mounting, easy to install switch into panel.

R13-57  - 

