



R13-83 · 84 · 92 · 101

Screw Type

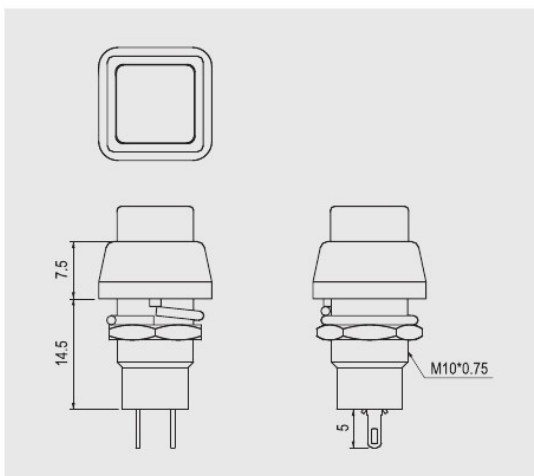

Rating
3A 125V AC 1A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

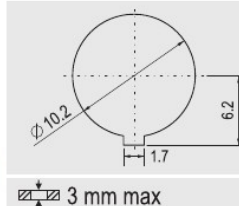

FEATURES

- * MATERIAL: Frame is ABS (UL flame: 94HB). Terminals are silver plated brass. Base is phenolic.
- * Mounted by nut.

R13- -

BUTTON	FUNCTION	TERMINAL
8 3 	A 	0 5 SO
8 4 	B 	
9 2 	* () =momentary	
1 0 1 		

