


R3-44 A

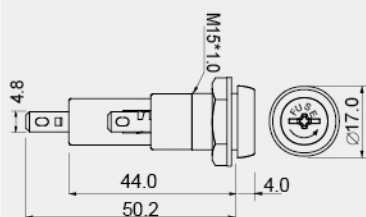

(4.8mm)0.187"
Quick connect

15A 250V AC

0.5~4.0mm

FEATURES:

- Material:
Frame: phenolic(UL flame: 94V-1).
Cap: PBT(UL flame: 94V-0).
Terminal: tin plated brass.
- Mounted by nut.
- Metal or plastic nut is optional.

	CAP	FUSE	
A	Bayonet type (tool release)	$\varnothing$ 6.35*30mm $\varnothing$ 6.35*31.8mm	
B	Bayonet type (tool release)	$\varnothing$ 5.0*20mm	
C	Screw type (tool release)	$\varnothing$ 6.35*30mm $\varnothing$ 6.35*31.8mm	

CUT-OUT

