


R3-44 A

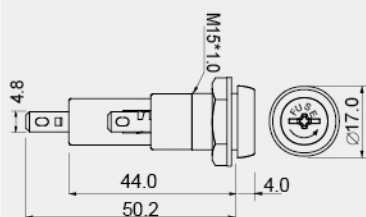

(4.8mm)0.187"
Quick connect

15A 250V AC
0.5~4.0mm

FEATURES:

- Material:
Frame: phenolic(UL flame: 94V-1).
Cap: PBT(UL flame: 94V-0).
Terminal: tin plated brass.
- Mounted by nut.
- Metal or plastic nut is optional.

A

CAP

Bayonet type
(tool release)



FUSE

Ø 6.35*30mm
Ø 6.35*31.8mm



B

Bayonet type
(tool release)



Ø 5.0*20mm



C

Screw type
(tool release)



Ø 6.35*30mm
Ø 6.35*31.8mm



CUT-OUT

