


R3-61

IP56

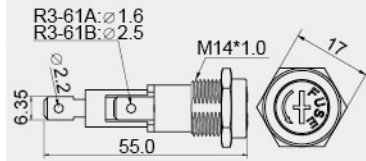

(6.4mm)0.250"
Quick connect

10A 250V AC

FEATURES:

- Material:
Frame: PC (UL flame: 94V-2).
Cap: PBT (UL flame: 94V-0).
Terminal: nickel plated brass.
- Mounted by nut.

TERMINAL HOLE

A $\varnothing 1.6$ mm

B $\varnothing 2.5$ mm

CAP

Screw type
(tool release)

FUSE

$\varnothing 6.35 \times 30$ mm

$\varnothing 6.35 \times 31.8$ mm

CUT-OUT

