


R13-205

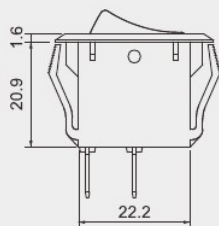

16A 12V DC
10A 28V DC
6A 14Vt

FEATURES

* Watertight boot (R13-205-20) is optional (refer page 86).



10A 28V, 16A 12VDC UL61058
for A, A2, A3, B, B2, BF, B2F, C3, D3,
F3, I3, L, LF



10A 28V DC, 16A 12VDC
for A, A2, A3, B, B2, BF, B2F, C3, D3,
F3, I3, L, LF

LR40128



10A 28V DC, 6A 14Vt
for A, B, L

FUNCTION

A OFF ON
2P SPST

A 2 OFF ON
2P SPST

A 3 OFF ON
2P SPST

B OFF ON
3P SPST
(BULB)

B F OFF (ON)
3P SPST
(BULB)

B 2 OFF ON
3P SPST
(BULB/LED)

B 2 F OFF (ON)
3P SPST
(LED)

C 3 ON ON
3P SPDT

D 3 ON OFF ON
3P SPDT

F 3 OFF (ON)
2P SPST

I 3 (ON) OFF (ON)
3P SPDT

L OFF ON
4P SPST
(LED)

L F OFF (ON)
4P SPST
(LED)

TERMINAL

0 1 .250" SQ

0 5 SO

Cut-out

X

Y

	X	Y
0.75~3.0	27.6±0.1	13.8±0.1
3.0~4.0	27.8±0.1	13.8±0.1
4.0~5.0	28.0±0.1	13.8±0.1

ROCKER

