

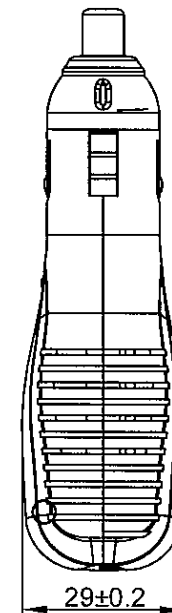
 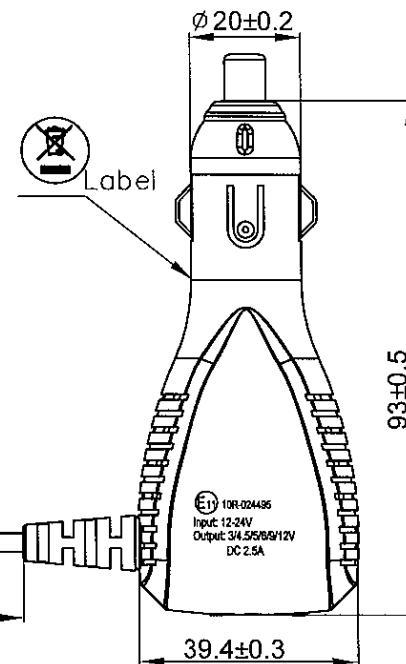
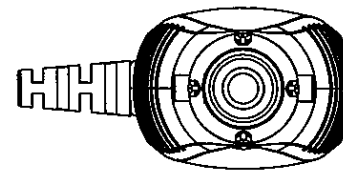
 
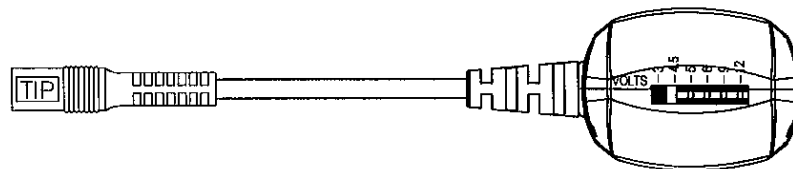



Model	A13-148B	
Rating	Input: 12V/24V	
Insulation Resistance	DC 500V 100M Min	
Voltage Breakdown	AC 1000V 1minute	
Operating Temperature	0 ° C~60 ° C	
Description	Auto plug-in power supplier with 6ft wire and plug	
Feature	withstand momentary Protection for short	
	6 steps output voltage :3/4.5/5/6/9/12V	
	Output current :2500mA	
	Green Led on(power on)	
Test item	Output Voltage Range	Output Voltage (2.5A)
12~24VDC	3V	2.7V~3.3V
12~24VDC	4.5V	4V~4.95V
12~24VDC	5V	4.5V~5.5V
12~24VDC	6V	8.6V~9.5V
12~24VDC	9V	7.1V~9.9V
12V	12V	(11~12.5V)
12.8V	12V	(11~12.5V)
13.8V	12V	(11~12.5V)
24V	12V	(11~12.5V)



(O)5528
(A)23507
(B)4017
(F)35MP
(G)3011
(M)5521

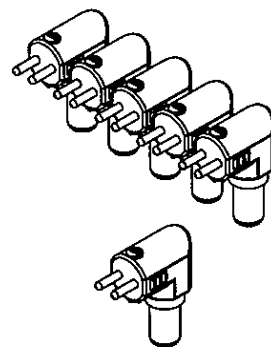

 USB TIP PLUG



MINI USB TIP PLUG

				Draw	Check	Approval	SCI No.	1250900	Model Name	POWER ADAPTER
				方 婷 麗			Customer No.	112-A13-148	Model No.	A13-148B1-W6
Date	Name	Description	NO	07/15/'10			Unit	mm	SHIN CHIN INDUSTRIAL CO., LTD.	