


Rating	Input	12-24 V DC
	Output	USB+Micro USB - 5V 2.1A max.
Insulation Resistance		DC 500V 100M ohm Min.
Dielectric Strength		AC 1000V 1 minute
Operation Temperature		-20°C~60°C
Operation Force to plug-in/pull-out		2~10Kgf
Fuse		3A glass tube

MATERIAL OF PLUG:

Housing: black, ABS (UL flame:94V-HB).

Top contact: nickel plated brass.

Spring contact: nickel plated spring steel.

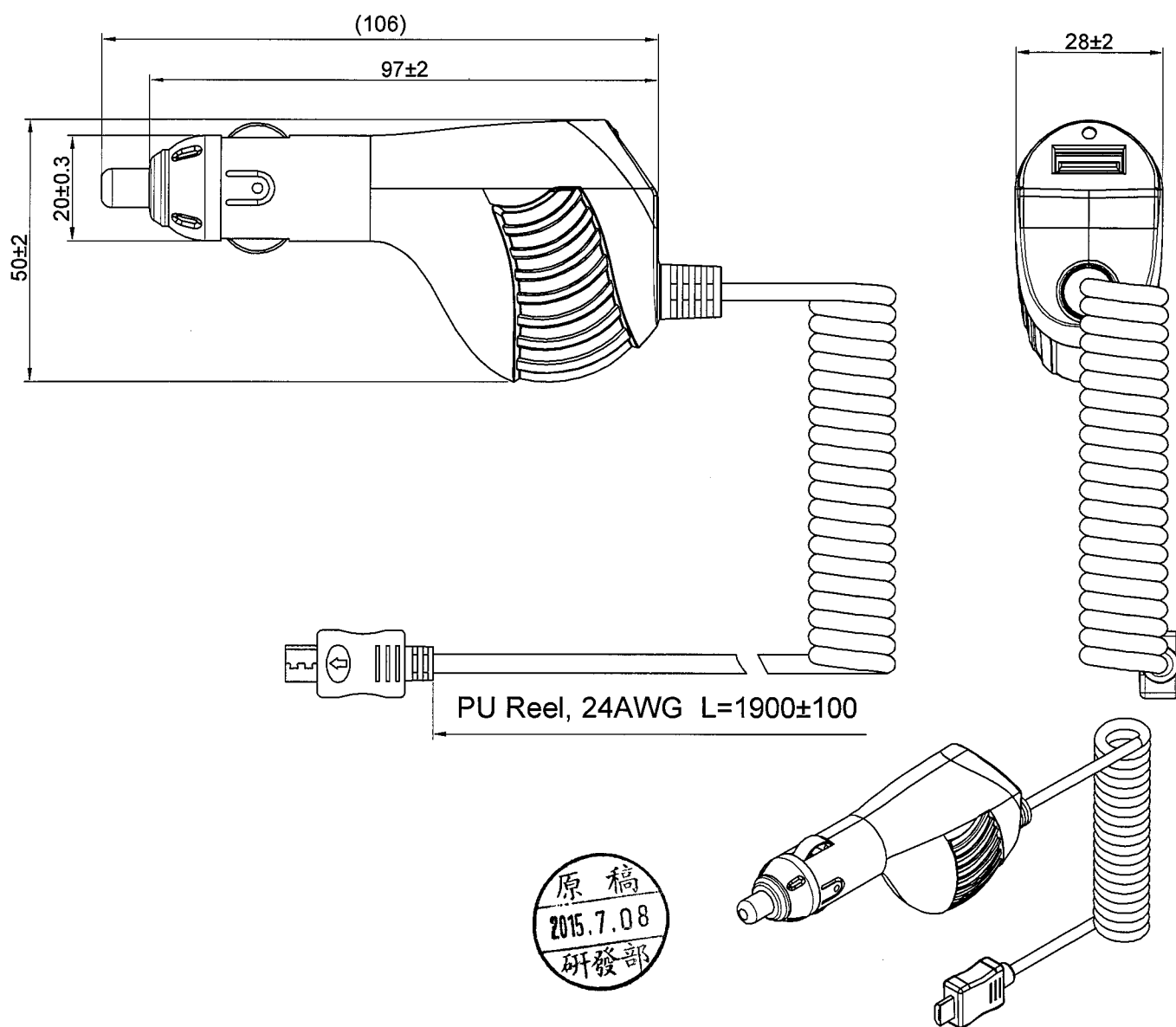

					△	
					△	
Date	Name	Description				No.
Drawn	Checked	Approved	SCI BOM No.	1251279	Model Name	Lighter Plug
Jam Chan			Customer No.	112-A13-201B-M	Model No.	A13-201B
5/26/15	7/7/15	7/7/15	Unit	mm	Shin Chin Industrial Co., Ltd.	
						Rev. 0