



R13-130.136



Screw Type

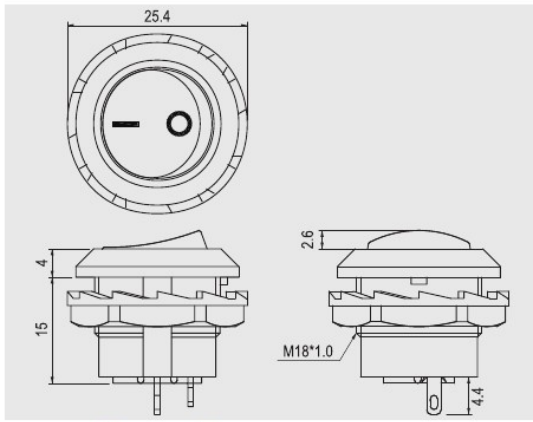


Rating
10A 125V AC 6A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out for R13-130,136

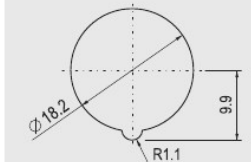

6 mm max

Cut-out for R13-49

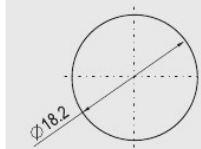


6 mm max

R13-49



Screw Type

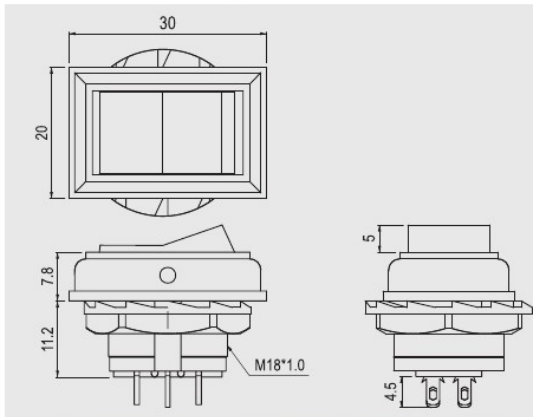

FEATURES

- * MATERIAL: Actuator is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Phenolic base.
- * Mounted by nut.

R13- -

ROCKER	FUNCTION	TERMINAL
1 3 0 	A OFF 2P SPST ON	0 5 SO
1 3 6 	B ON 6P DPDT ON	
4 9 	C ON 3P SPDT ON	

