


R13-608

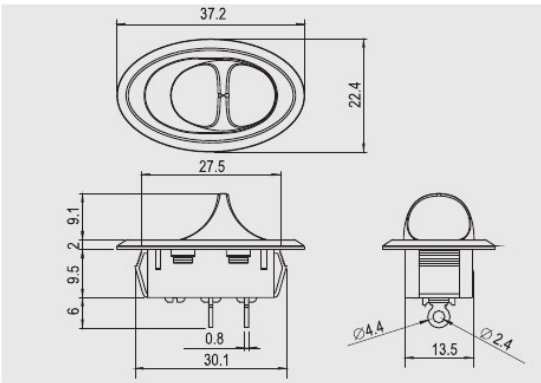

Rating
16A 125V AC 1/3HP 10A 250V AC 1/2HP
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

FEATURES

- * MATERIAL: Frame and Actuator are nylon (UL flame:94V-2). Terminals are silver plated brass.
- * Snap-in mounting, easy install switch into panel.

	X	Y
	X	Y
0.75~1.25	27.8-0.1	13.8+0.1
1.25~2.0	28.0-0.1	13.8+0.1
2.0~3.0	28.2-0.1	13.8+0.1

R13-608 1 -

FUNCTION			TERMINAL	
A		2P SPST	0 2	.187" SQ
C		3P SPDT	0 5	SO
D		3P SPDT		