



R13-509

Screw Type

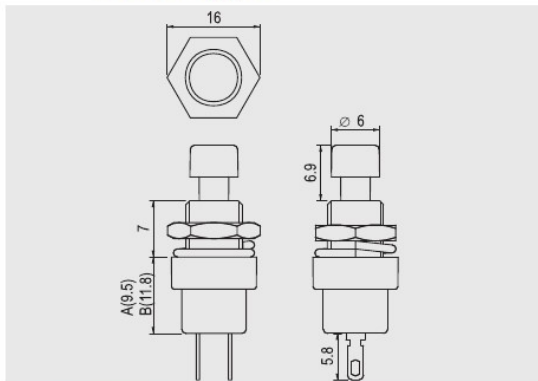

Rating
3A 125V AC 1.5A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out

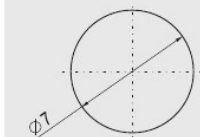

3 mm max

FEATURES

- * MATERIAL: Actuator and Frame are nylon (UL flame: 94V-2). Terminals are silver plated brass. Base is phenolic.
- * Mounted by nut.

R13-509 -

FUNCTION	TERMINAL
A 2P SPST	0 5 SO
B 2P SPST	

* () =momentary