


# R3-14D

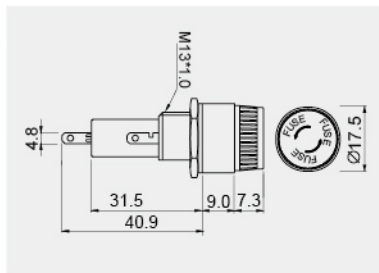

(4.8mm)0.187"  
Quick connect

10A 250V AC  
0.5~6.5mm

## FEATURES:

- Material:  
Frame and cap: phenolic(UL flame: 94V-1).  
Terminal: nickel plated brass.
- Mounted by nut.

CAP

Bayonet type

FUSE

Ø 6.35\*30mm

Ø 6.35\*31.8mm

## CUT-OUT

