


R3-46 A

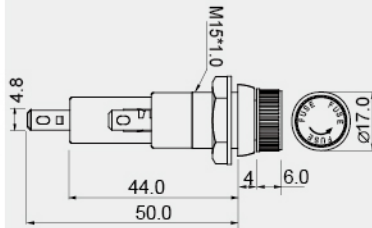

(4.8mm)0.187"
Quick connect

15A 250V AC
0.5~ 4.5mm

FEATURES:

- Material:
Frame: phenolic(UL flame: 94V-1).
Cap: PBT(UL flame: 94V-0).
Terminal: tin plated brass.
- Mounted by nut.
- Metal or plastic nut is optional.

A

CAP

Bayonet type

B

Bayonet type

C

Screw type

FUSE

Ø 6.35*30mm
Ø 6.35*31.8mm

Ø 5.0*20mm

Ø 6.35*30mm
Ø 6.35*31.8mm

UL

UL

UL

CUT-OUT

