


R3-83-01-1 310 **Waterproof / ATC Blade Fuse**

IP56

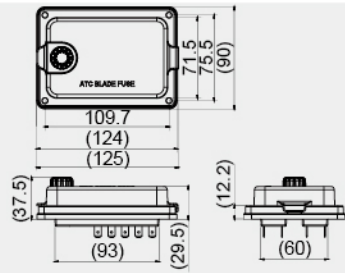

(6.4mm)0.250" Quick connect

32V DC max

FUSE



 
ATO/ATC BLADE FUSE

INDICATOR LIGHT


☒ With LED

☐ W/O LED

CIRCUIT DIAGRAM



CUT-OUT

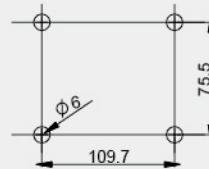

FEATURES:

- Material:
 Base: PBT (UL flame: 94V-0).
 Cap: PC (UL flame: 94V-2).
 Terminal: nickel plated brass.
- Wire size: #10-16 AWG.
- Mounting torque rating: 8in-lb (0.9 Nm) max.
- Output terminal rating: 25A max per circuit.
- Red LED indicates when fuse is broken.
- Insulating cover design for dust proof.
- Circuit Diagram x 10 sets