
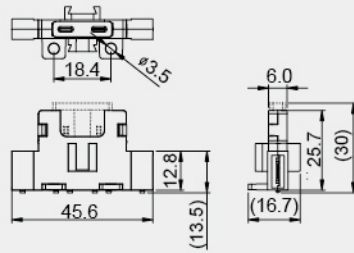


R3-98

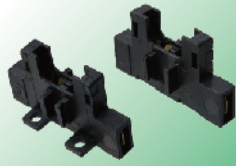

 (6.4mm)0.250"
Quick connect

32V DC

FEATURES:

- Material:
Frame: nylon(UL flame: 94V-0).
Terminal: brass.
- Input terminal rating: 0.25" terminal (30A max).
- Output terminal rating: 0.25" terminal (30A max).
- Side stackable for multiple block configurations.
- unavailable in UK, Netherland, Belgium and Luxemburg markets.

FUSE



ATO / ATC BLADE FUSE

CUT-OUT

