


R3-9

UL US

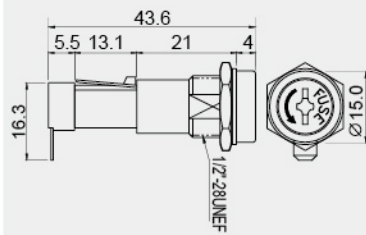

(4.8mm)0.187"
Quick connect

0.5~4.5mm MAX

FEATURES:

- Material:
Frame and cap: PBT(UL flame: 94V-0).
Terminal: tin plated brass.
- Mounted by nut.
- Metal or plastic nut is optional.

A

CAP

Bayonet type
(tool release)



FUSE



Ø6.35*30mm
Ø6.35*31.8mm

RATING

15A 250V
AC

B

Bayonet type
(tool release)



Ø5.0*20mm

10A 250V
AC

C

Screw type
(tool release)



Ø6.35*30mm
Ø6.35*31.8mm

15A 250V
AC

C O

Screw type
(tool release)



Ø6.35*30mm
Ø6.35*31.8mm

15A 250V
AC

IP55

CUT-OUT

