


Test Voltage Range	5V~30V DC
Insulation Resistance	DC 500V 100M Ω Min
Dielectric Strength	AC 1500V 1 Second
Operating Temperature	-0°C~+60°C

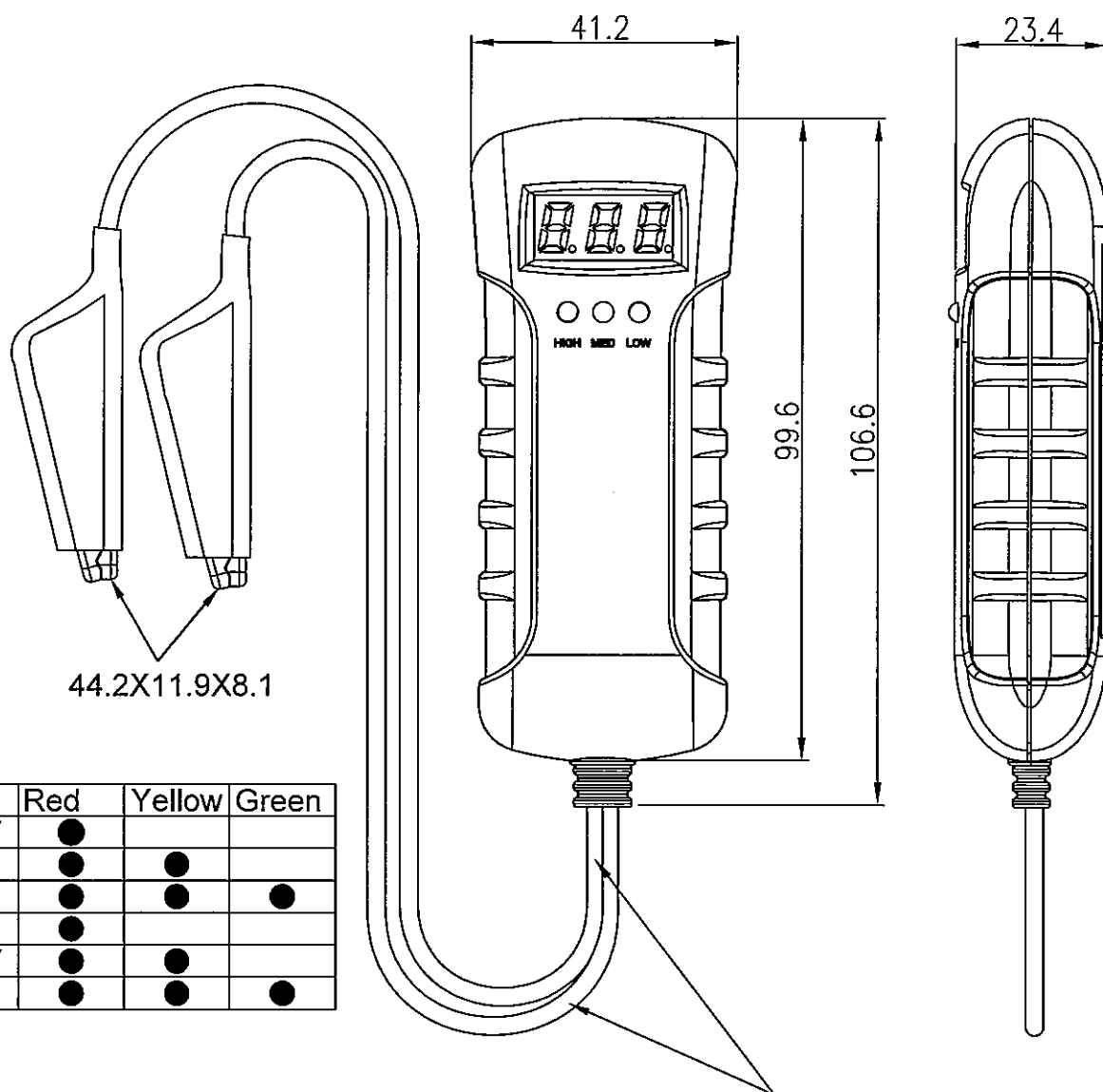

	Red	Yellow	Green
5V~11.7V	●		
11.8V~12.4V	●	●	
12.5V~15.9V	●	●	●
16V~23.5V	●		
23.6V~24.9V	●	●	
25V~30V	●	●	●

UL1803 24AWG 紅/黑色 L(Including Clamp)=622±30 mm



A4

								△
								△
Date	Name	Description						NO
Drawn	Checked	Approved	SCI BOM No.		Model Name	Battery Tester		
胡朝鈺		<i>DZL</i>	Customer No.	112-R8-124B	Model No.	R8-124B		REV.
2008/5/20		<i>5/20/08</i>	Unit	mm	SHIN CHIN INDUSTRIAL CO., LTD.			1