


LI-ION BATTERY 40MAH 3.7V

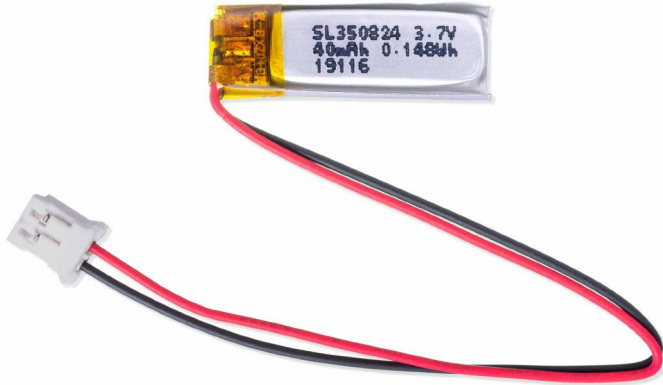

DESCRIPTION

This lithium-ion battery is small, light and durable. Through standard JST 2mm female connector, it will yield 3.7V which will supply your projects for a whole day (and night!). Furthermore, the battery has an implemented protection system, which prevents high voltages (prevents over-charging), undervoltage and short circuit. That way it protects the battery, increases its lifetime and protects you from possible accidents!

This small battery is practical for smartwatch projects or other projects where battery dimensions are crucial.

- **Nominal voltage:** 3.7V
- **Capacity:** 40mAh, 0.15Wh
- **Dimensions:** 24 x 8.5 x 3.5mm
- **Standard JST-PH-2mm connector**

DISCLAIMER: This battery has to be charged with a special charged that uses **CC/CV** principle. Li-ion batteries are dangerous! Read our tutorial (link in the top right corner) before use.

FEATURES

- Nominal voltage: 3.7V
- Capacity: 40mAh, 0.15Wh
- Standard JST-PH-2mm connector
- Dimensions: 24 x 8.5 x 3.5 mm / 0.9 x 0.3 x 0.1 inch

USEFUL LINKS

- [MSDS](#)

OTHER IMAGES

